

**Board-to-Wire Connectors
Pitch 3.96 mm Series CGM**

Housings CGM series single row



SPECIFICATION:



Operating Voltage (Max.):	250 V
Operating Current (Nom.):	5 A
Operating Temperature:	-25°C to 85°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	10 mΩ
Dielectric Strength:	1,500 Vac

MATERIAL:

Material (Housing):	nylon 66
Flammability Class:	UL 94 V-2

HANDLING:

Packaging:	bulk
------------	------

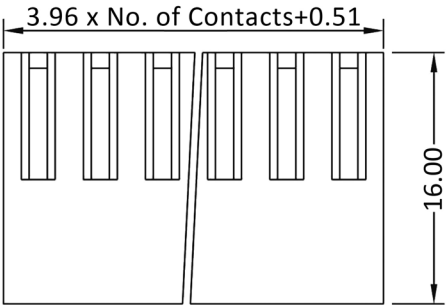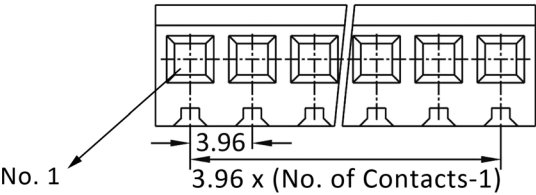

Order Information

Identifier:	No. of Contacts:
CGM	#
Housing series CGM pitch 3.96 mm single row	2: 1 x 2
	3: 1 x 3
	4: 1 x 4
	:
	20: 1 x 20