

**SPECIFICATION:**



Operating Voltage (Max.): 250 V  
 Operating Current (Nom.): 5 A  
 Operating Temperature: -25°C to 85°C  
 Insulation Resistance (Min.): 1000 MΩ  
 Contact Resistance (Max.): 10 mΩ  
 Dielectric Strength: 1,500 Vac

**MATERIAL:**

Material (Terminal): brass, tin plated  
 Material (Housing): nylon 66  
 Flammability Class: UL 94 V-2  
 Material (Contact Area): brass, tin plated

**HANDLING:**

Packaging: bulk

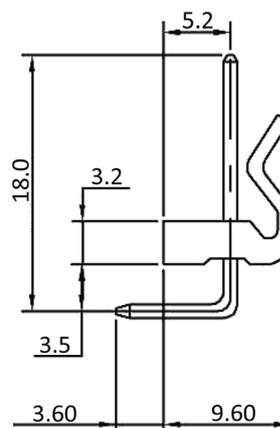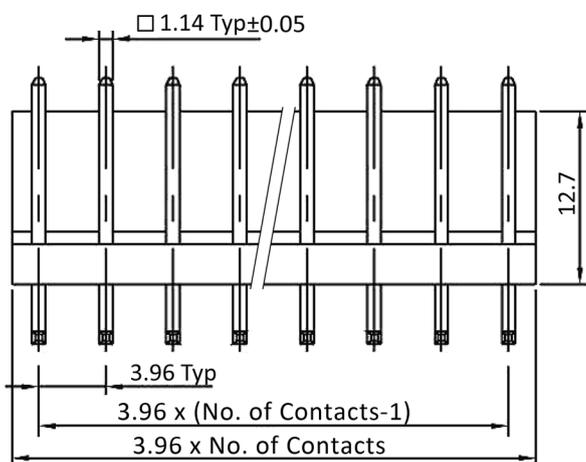

**Order Information**

Identifier:	No. of Contacts:	Version:
<b>CGV</b>	<b>#</b>	<b>W</b>
Wafer series CGM pitch 3.96 mm single row	2: 1 x 2	angled
	3: 1 x 3	
	4: 1 x 4	
	:	
	20: 1 x 20	