

Board-to-Wire Connectors
Pitch 3.96 mm Series CGM

Crimp Contacts for housing CGM



SPECIFICATION:

AWG (Max.):	AWG 18
AWG (Min.):	AWG 24
Operating Voltage (Max.):	250 V
Operating Current (Nom.):	5 A
Operating Temperature:	-25°C to 85°C
Cable Diameter (Max.):	2.8 mm
Contact Resistance (Max.):	10 mΩ
Dielectric Strength:	1,500 Vac




MATERIAL:

Material (Terminal):	brass, tin plated
Material (Contact Area):	brass, tin plated

HANDLING:

Packaging:	taped
------------	-------

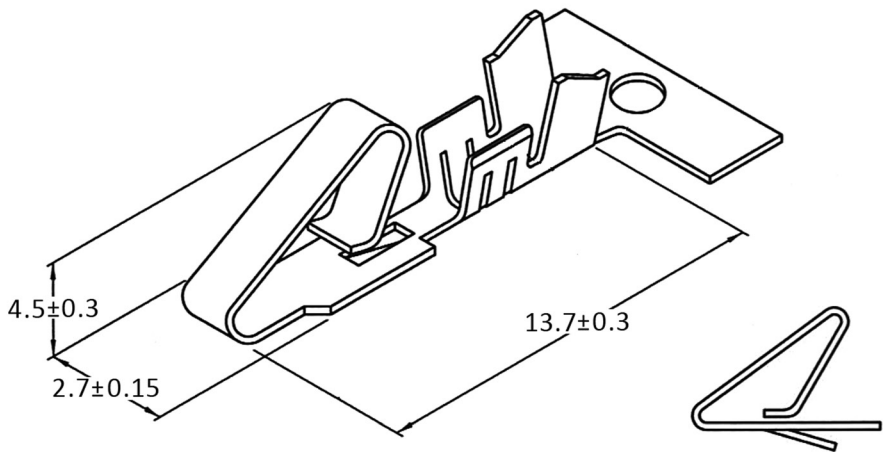

Order Information

Identifier:

CKM

Terminal for CGM series

Packing Unit:

#

E: 100 pcs. separately cut

7K: roll with 7.000 pieces