

Board-to-Wire Connectors Pitch 2.5 mm Series H33

Crimp Contacts for housing H33H



SPECIFICATION:

Operating Voltage (Max.):	250 V
Operating Current (Nom.):	3 A
Operating Temperature:	-25°C to 85°C
Contact Resistance (Max.):	10 mΩ
Dielectric Strength:	1,000 Vac
AWG (Max.):	AWG 22
AWG (Min.):	AWG 28
Cable Diameter (Max.):	1.9 mm

MATERIAL:


Material (Terminal):	brass, tin plated
Material (Contact Area):	brass, tin plated

HANDLING:

Packaging:	reel
------------	------

TOLERANCE:

.X:	± 0.25
.XX:	± 0.20

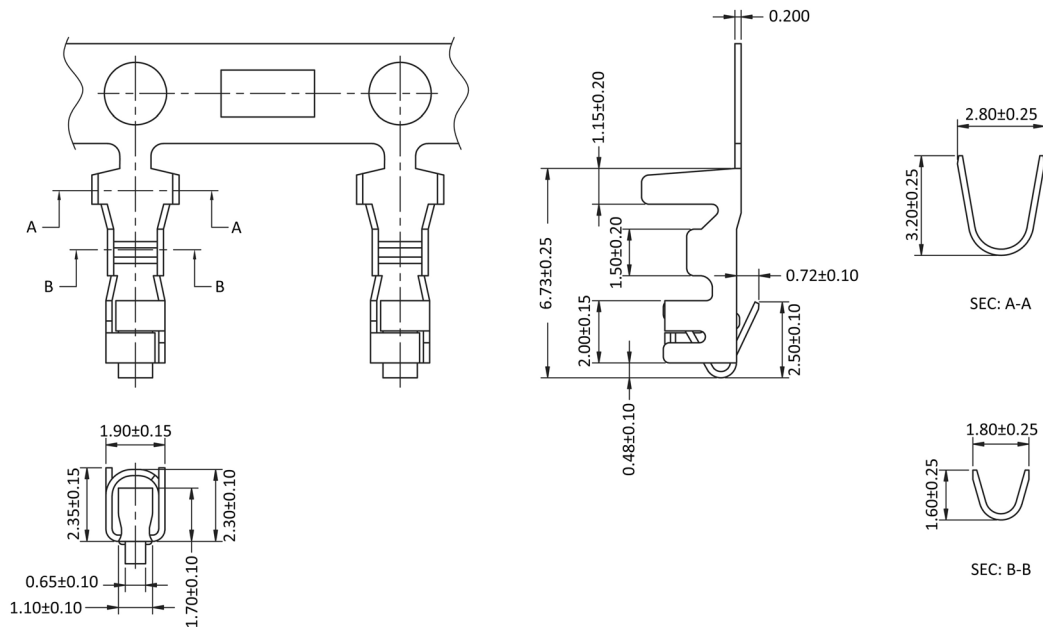

Order Information

Identifier:

CR33K

Terminal for H33H series

Packing Unit:

8

roll with 8.000 pieces