


Board-to-Wire Connectors Pitch 4.2 mm Series H4D

Crimp Contacts for housing H4D



SPECIFICATION:

AWG (Max.):	AWG 18
AWG (Min.):	AWG 24
Operating Voltage (Max.):	600 V
Operating Current (Nom.):	9 A
Operating Temperature:	-25°C to 85°C
Cable Diameter (Max.):	2.8 mm
Contact Resistance (Max.):	10 mΩ
Dielectric Strength:	1,500 Vac

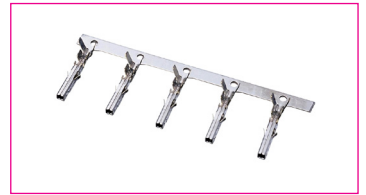

MATERIAL:



Material (Terminal):	brass, tin plated
----------------------	-------------------

HANDLING:


Packaging:	taped
------------	-------

TOLERANCE:


.X:	± 0.25
.XX:	± 0.13

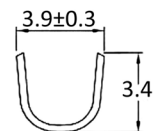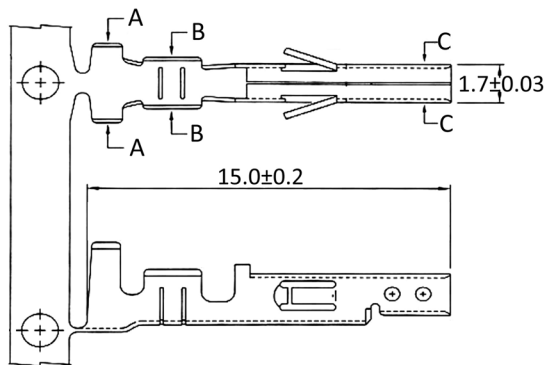

Section A-A

 

Section B-B

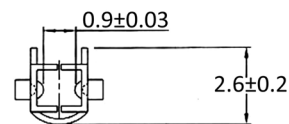

Section C-C

Order Information

Identifier:

CRATX

Terminal for female housing H4 series

Packing Unit:

#

empty: 100 pcs. separately cut

6K: roll with 6.000 pieces