

**SPECIFICATION:**

Operating Voltage (Max.): 250 V  
 Operating Current (Nom.): 7 A  
 Operating Temperature: -25°C to 85°C  
 Insulation Resistance (Min.): 1000 MΩ  
 Contact Resistance (Max.): 10 mΩ  
 Dielectric Strength: 1,500 Vac

**MATERIAL:**


Material (Terminal): brass, tin plated  
 Material (Housing): nylon 66  
 Flammability Class: UL 94 V-0  
 Material (Contact Area): brass, tin plated

**HANDLING:**

Packaging: bulk

**TOLERANCE:**

.X: ± 0.35  
 .XX: ± 0.25

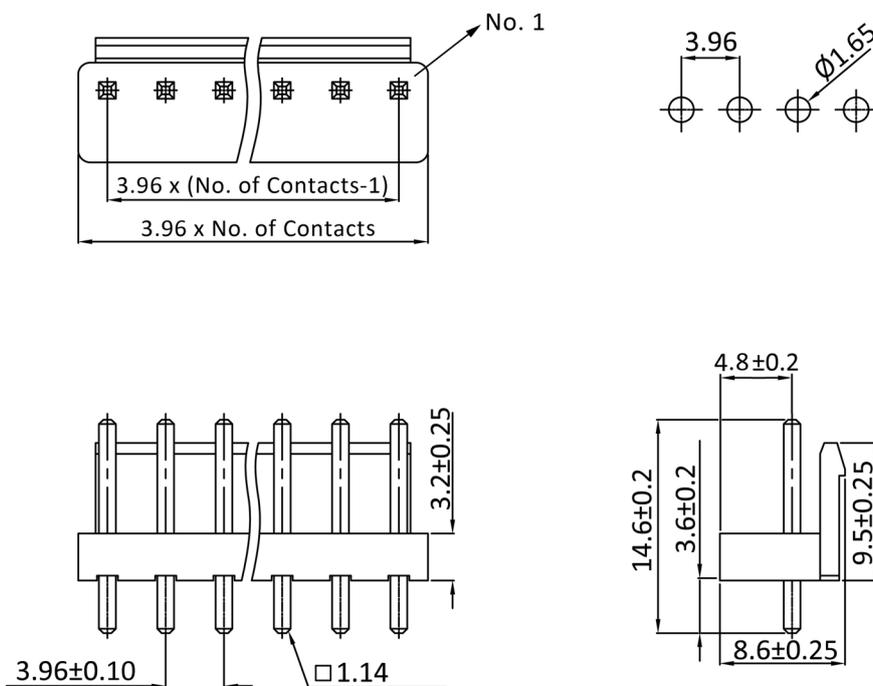

**Order Information**

<b>Identifier:</b> CSV	<b>No. of Contacts:</b> #	<b>Version:</b> G	<b>Pitch:</b> 3
Wafer series CVG pitch 3.96 mm single row	2: 1 x 2 3: 1 x 3 4: 1 x 4 : 15: 1 x 15	straight	Pitch 3.96 mm