

Board-to-Wire Connectors Pitch 2.0 mm Series CVG

Wafers for Housing Series CVG single
row, straight



SPECIFICATION:

Current rating: 1 A
Voltage rating: 100 V
Insulation resistance: 1000 MΩ min.
Contact resistance: 20 mΩ max.
Dielectric voltage: 800 V AC
Operation temperature: -25 °C to +85 °C

MATERIAL:

Housing: Nylon 66 white UL94V-0
Contacts: Brass

FINISH:

Contacts: Tin plated



HANDLING:

Packing: Bulk

TOLERANCE:

.X ± 0.25
.XX ± 0.20

RoHS
COMPLIANT

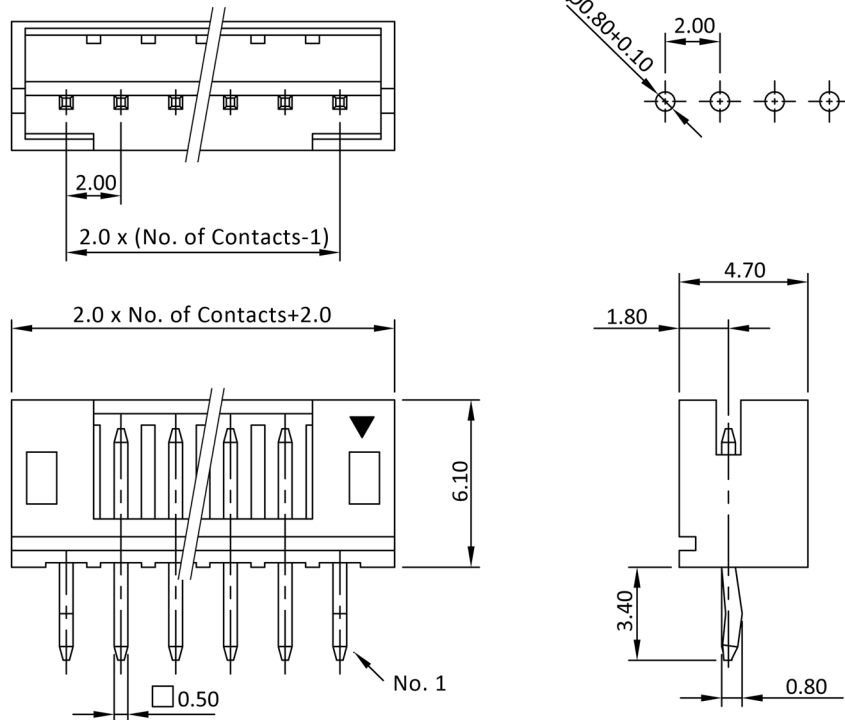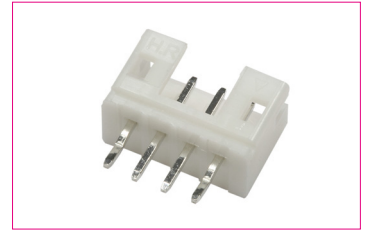

Order-Information

Identifier:	No. of contacts:	Version:	Pitch:
CSV	#	G	2
Wafer Series CVG Pitch 2.0 mm single row straight	2: 1 x 2 3: 1 x 3 4: 1 x 4 : 16: 1 x 16	G: straight	2: Pitch 2.0 mm