

Board-to-Wire Connectors Pitch 3.96 mm Series CVG

Housing CVG series single row



SPECIFICATION:

Operating Voltage (Max.):	250 V
Operating Current (Nom.):	7 A
Operating Temperature:	-25°C to 85°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	10 mΩ
Dielectric Strength:	1,500 Vac

MATERIAL:





Material (Housing):	nylon 66
Flammability Class:	UL 94 V-0

HANDLING:

Packaging:	bulk
------------	------

TOLERANCE:

.X:	± 0.25
.XX:	± 0.15

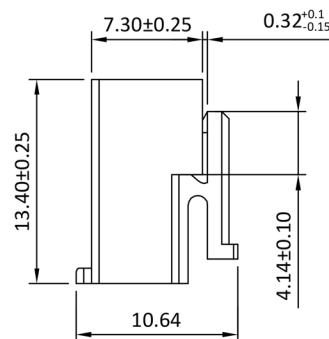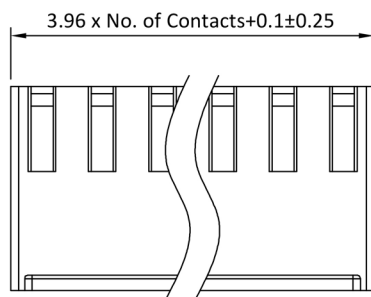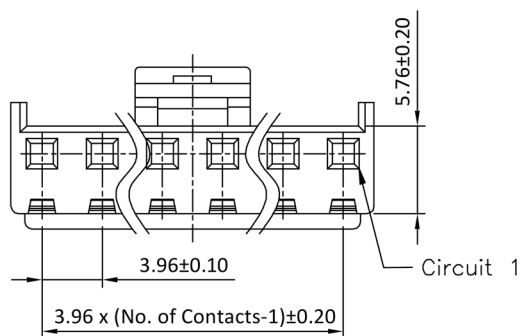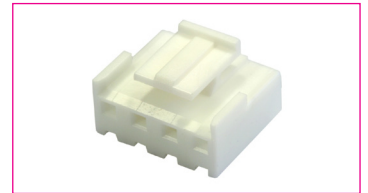

Order Information

Identifier:	No. of Contacts:		Pitch:
CVG	#	/	3
Housing series CVG pitch 3.96 mm single row	2: 1 x 2		Pitch 3.96 mm
	3: 1 x 3		
	4: 1 x 4		
	:		
	15: 1 x 15		