

## Board-to-Wire Connectors Pitch 2.0 mm Series CVG

## Crimping Contacts for Housing Series CVG single row



### SPECIFICATION:

Current rating:	1 A
Voltage rating:	100 V
Contact resistance:	20 mΩ max.
Dielectric voltage:	800 V AC
Wire range:	AWG24-30
Insulation outer diameter:	1.5 mm max.
Operation temperature:	-25 °C to +85 °C

### MATERIAL:

Contact:	Phosphorbronze
----------	----------------

### FINISH:

Contact:	Tin plated
----------	------------




### HANDLING:

Packing:	Reel with 10K, otherwise separately cut
----------	---


### TOLERANCE:

.X	± 0.20
.XX	± 0.10


RoHS  
COMPLIANT

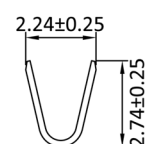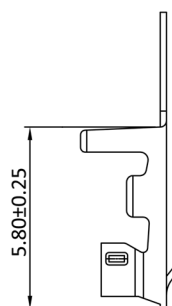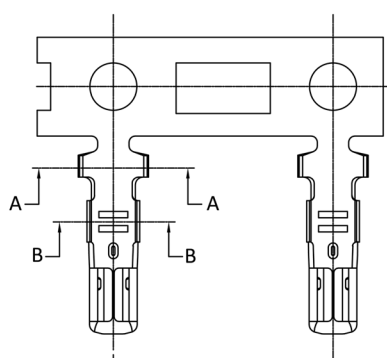

SEC: A-A

 

SEC: B-B

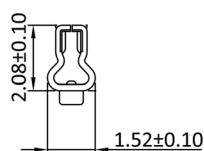

### Order-Information

Identifier:

CVK2

Terminal for CVG-Series single row

Packing unit:

#

empty: separately, cut  
/10K: reel with 10.000 pcs.