

Female Header Pitch 2.0 mm angled

Single row, height 6.35 mm



SPECIFICATION:

Current rating: 2 A
Insulation resistance: 1000 MΩ min.
Contact resistance: 20 mΩ max.
Dielectric voltage: 500 V AC
Operation temperature: -40 °C to +105 °C

MATERIAL:

Housing: Nylon 6T UL94V-0
Contacts: Copper alloy





HANDLING:

Processing: Wave soldering
Packing: Tube

TOLERANCE:

.X ± 0.25
.XX ± 0.20

RoHS
COMPLIANT

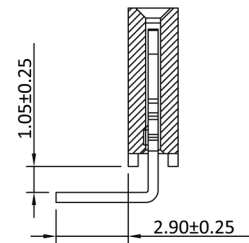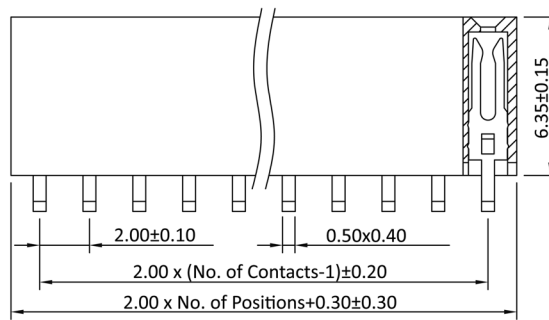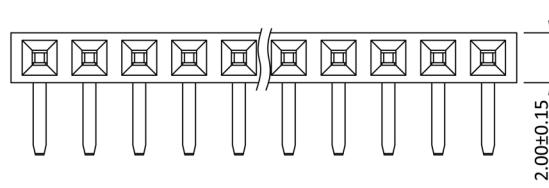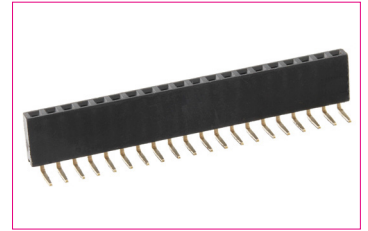

Recommended PCB Layout
(PCB Tolerance ±0.05)

Order-Information

Identifier:	No. of contacts:	Contact Plating:
FHR63S	#	#
Female Header Pitch 2.0 mm single row angled Height 6.35 mm	3: 1 x 3	G: Gold Flash *
	4: 1 x 4	S: Selective
	5: 1 x 5	
	:	
	40: 1 x 40	

* = standard