

Female Header Pitch 2.0 mm straight

Double row, height 4.3 mm



SPECIFICATION:

Current rating: 2 A
Insulation resistance: 1000 MΩ min.
Contact resistance: 20 mΩ max.
Dielectric voltage: 500 V AC
Operation temperature: -40 °C to +105 °C

MATERIAL:

Housing: Nylon 6T UL94V-0
Contacts: Copper alloy

 



HANDLING:

Processing: Wave soldering
Packing: Tube

TOLERANCE:

.X ± 0.25
.XX ± 0.20

RoHS
COMPLIANT

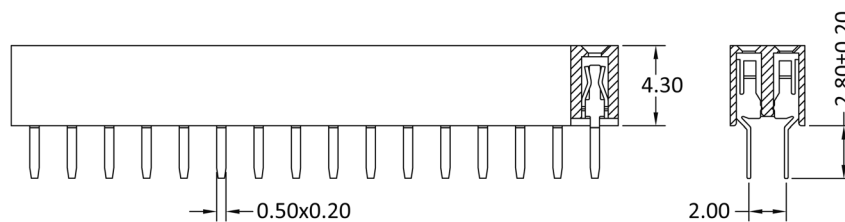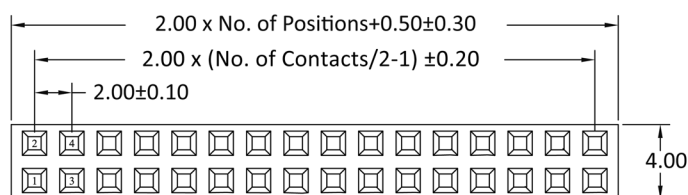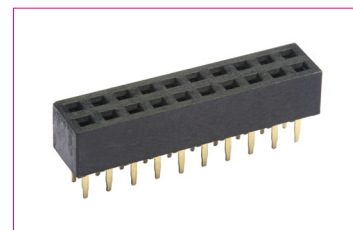

Recommended PCB Layout
(PCB Tolerance ± 0.05)

Order-Information

Identifier:	No. of contacts:	Contact Plating:
FHS43D	#	#
Female Header Pitch 2.0 mm double row straight Height 4.3 mm	2: 2 x 1 4: 2 x 2 6: 2 x 3 : 80: 2 x 40	G: Gold Flash * S: Selective

* = standard