

Board-to-Wire Connectors Pitch 5.08 mm Floppy

Power Connection 4 poles PCB, angled



SPECIFICATION:

Operating Voltage (Max.):	250 V
Operating Temperature:	-25°C to 85°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	10 mΩ
Dielectric Strength:	1,500 Vac

MATERIAL:



Material (Terminal):	brass, tin plated
Material (Housing):	nylon 66
Flammability Class:	UL 94 V-2
Material (Contact Area):	brass, tin plated

HANDLING:



Packaging:	bulk
------------	------

TOLERANCE:

.X:	± 0.35
.XX:	± 0.25

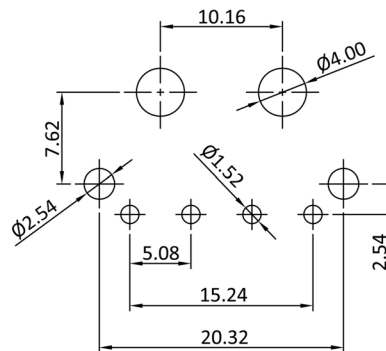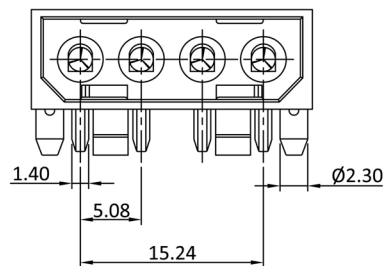

Recommended PCB Layout

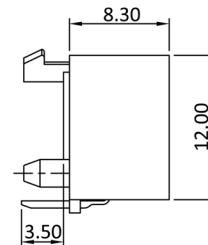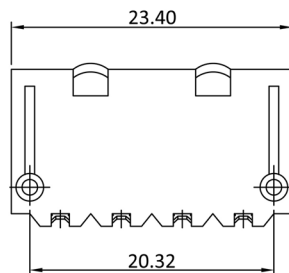

Order Information

Identifier:

FK05PW

Wafer 4 poles pitch 5.08 mm angled