

Board-to-Wire Connectors Pitch 2.0 mm Series H22H

Housing H22H Series single row



SPECIFICATION:

Current rating:	1 A
Voltage rating:	100 V
Insulation resistance:	1000 MΩ min.
Contact resistance:	20 mΩ max.
Dielectric voltage:	800 V AC
Operation temperature:	-25 °C to +85 °C

MATERIAL:

Housing:	Nylon 66 white UL94V-0
----------	------------------------




HANDLING:

Packing:	Bulk
----------	------

TOLERANCE:

.X	± 0.25
.XX	± 0.20

RoHS
COMPLIANT

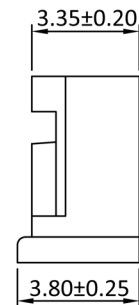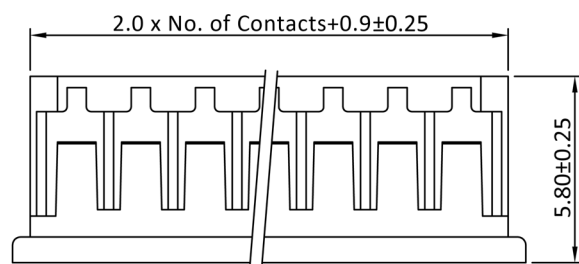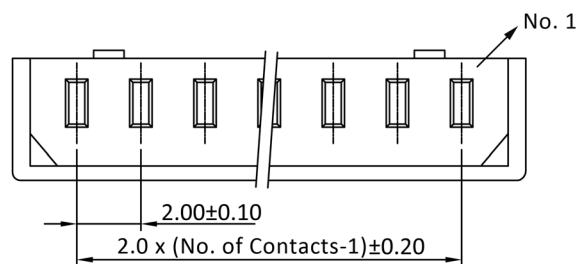

Order-Information

Identifier:

H22H

Housing Series H22H Pitch 2.0 mm single row

No. of contacts:

#

2: 1 x 2

3: 1 x 3

4: 1 x 4

:

15: 1 x 15