

Board-to-Wire Connectors Pitch 2.0 mm Series H2H

Housing H2H Series single row



SPECIFICATION:

Current rating:	1 A
Voltage rating:	130 V
Insulation resistance:	1000 MΩ min.
Contact resistance:	20 mΩ max.
Dielectric voltage:	800 V AC
Operation temperature:	-25 °C to +85 °C

MATERIAL:

Housing:	Nylon 66 black UL94V-2
----------	------------------------





HANDLING:

Packing:	Bulk
----------	------

TOLERANCE:

.X	± 0.25
.XX	± 0.20

RoHS
COMPLIANT

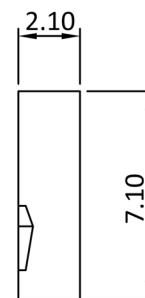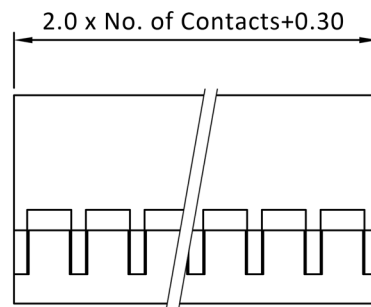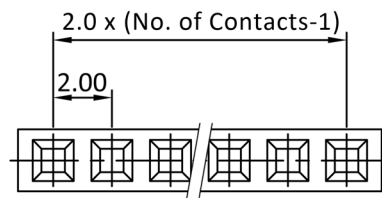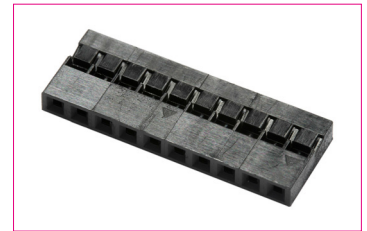

Order-Information

Identifier:

H2HS

Housing Series H2H Pitch 2.0 mm single row

No. of contacts:

#

2: 1 x 2

3: 1 x 3

4: 1 x 4

:

20: 1 x 20