

**Board-to-Wire Connectors
Pitch 2.5 mm Series H33**

Housing H33H series single row



SPECIFICATION:

Operating Voltage (Max.): 250 V
 Operating Current (Nom.): 3 A
 Operating Temperature: -25°C to 85°C
 Insulation Resistance (Min.): 1000 MΩ
 Contact Resistance (Max.): 10 mΩ
 Dielectric Strength: 1,000 Vac

MATERIAL:




Material (Housing): nylon 66
 Flammability Class: UL 94 V-0

HANDLING:

Packaging: bulk

TOLERANZ:

.X: ± 0.25
 .XX: ± 0.20

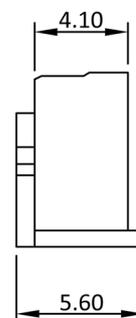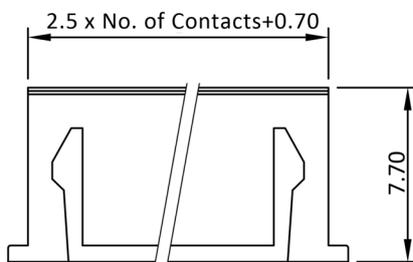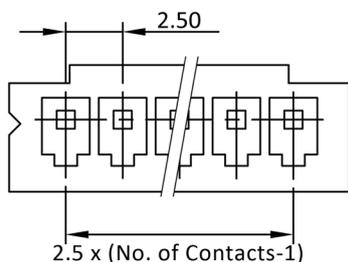

Order Information

Identifier:

H33H

Housing series H33H pitch 2.5 mm single row

No. of Contacts:

#

2: 1 x 2

3: 1 x 3

4: 1 x 4

:

15: 1 x 15