

**Board-to-Wire Connectors
Pitch 4.2 mm Series H4C**

Housings H4C series double row



SPECIFICATION:

Operating Voltage (Max.):	600 V
Operating Current (Nom.):	7 A
Operating Temperature:	-25°C to 85°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	10 mΩ
Dielectric Strength:	1,500 Vac

MATERIAL:




Material (Housing):	nylon 66
Flammability Class:	UL 94 V-2

HANDLING:

Packaging:	bulk
------------	------

TOLERANCE:

.X:	± 0.35
.XX:	± 0.25

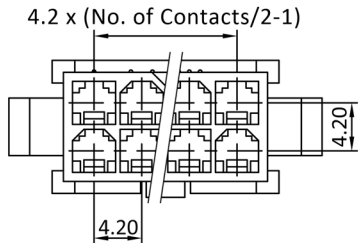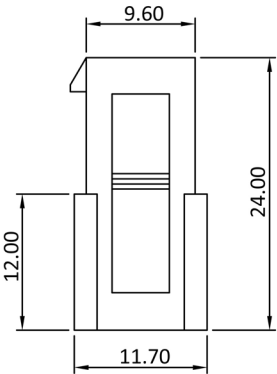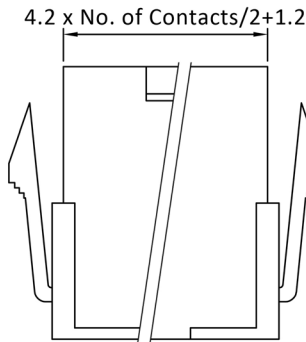

Order Information

Identifier:	No. of Contacts:
H4CD	#
Housing series H4 pitch 4.2 mm double row	2: 2 x 1
	4: 2 x 2
	6: 2 x 3
	8: 2 x 4