

**Board-to-Wire Connectors  
Pitch 4.2 mm Series H4C**

**Housings H4C series single row**



**SPECIFICATION:**

Operating Voltage (Max.):	250 V
Operating Current (Nom.):	7 A
Operating Temperature:	-25°C to 85°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	10 mΩ
Dielectric Strength:	1,500 Vac

**MATERIAL:**

Material (Housing):	nylon 66
Flammability Class:	UL 94 V-2

**HANDLING:**



Packaging:	bulk
------------	------

**TOLERANCE:**


.X:	± 0.35
.XX:	± 0.25



$4.2 \times \text{No. of Contacts} + 1.2$

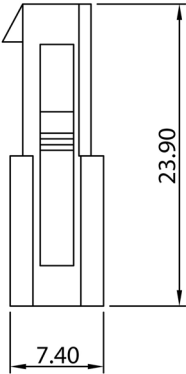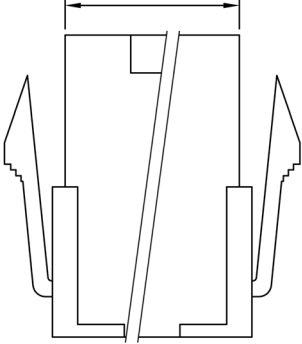

$4.2 \times (\text{No. of Contacts} - 1)$

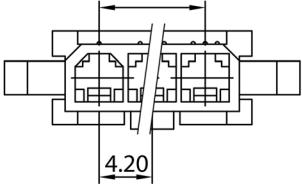

**Order Information**

Identifier:	No. of Contacts:
H4CS	#
Housing series H4 pitch 4.2 mm single row	2: 1 x 2
	3: 1 x 3
	4: 1 x 4