

**Board-to-Wire Connectors  
Pitch 4.2 mm Series H4D**

**Housings H4D series double row**



**SPECIFICATION:**

Operating Voltage (Max.):	600 V
Operating Current (Nom.):	9 A
Operating Temperature:	-25°C to 85°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	10 mΩ
Dielectric Strength:	1,500 Vac

**MATERIAL:**


Material (Housing):	nylon 66
Flammability Class:	UL 94 V-2

**HANDLING:**

Packaging:	bulk
------------	------

**TOLERANCE:**

.X:	± 0.35
.XX:	± 0.25

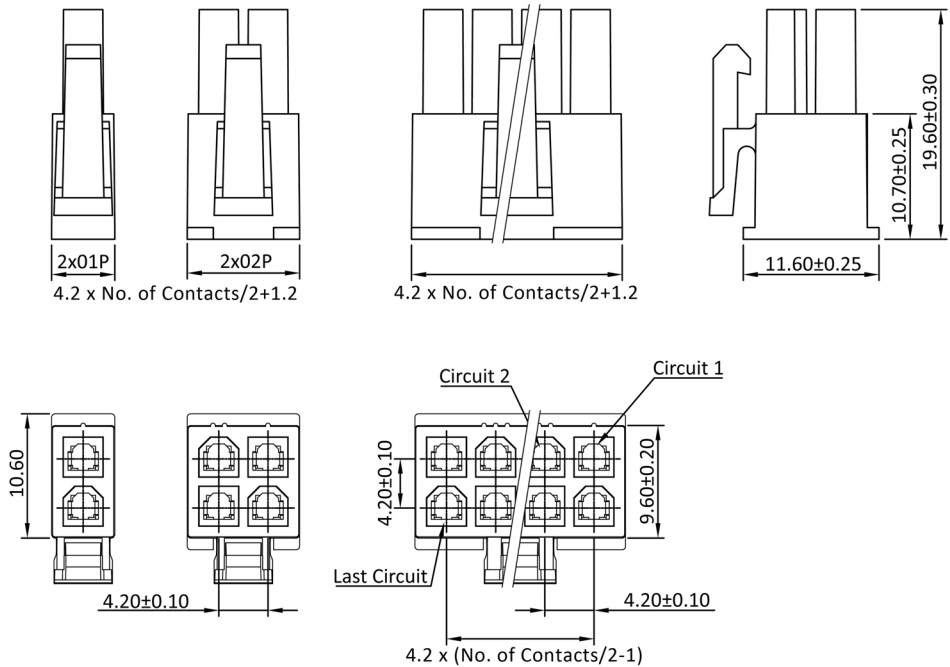

**Order Information**

Identifier:	No. of Contacts:
H4DD	#
Housing series H4 pitch 4.2 mm double row	2: 2 x 1
	4: 2 x 2
	6: 2 x 3
	8: 2 x 4