

**Board-to-Wire Connectors
Pitch 4.2 mm Series H4D**

Housings H4D series single row



SPECIFICATION:

Operating Voltage (Max.):	600 V
Operating Current (Nom.):	9 A
Operating Temperature:	-25°C to 85°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	10 mΩ
Dielectric Strength:	1,500 Vac

MATERIAL:

 

 

 




Material (Housing):	nylon 66
Flammability Class:	UL 94 V-2

HANDLING:

Packaging:	bulk
------------	------

TOLERANCE:

.X:	± 0.35
.XX:	± 0.25

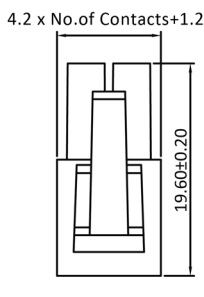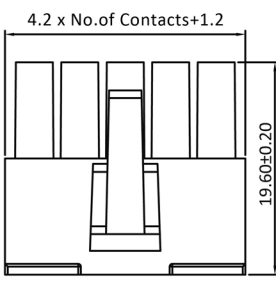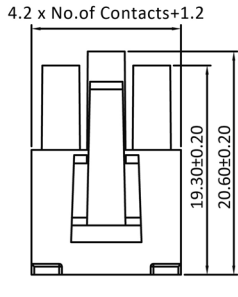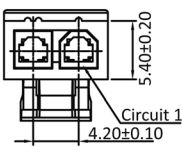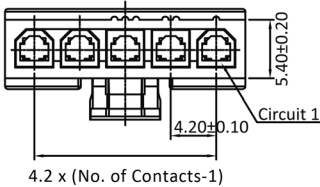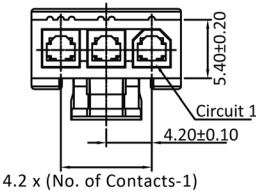

Order Information

Identifier:

H4DS

Housing series H4 pitch 4.2 mm single row

No. of Contacts:

#

2: 1 x 2

3: 1 x 3

4: 1 x 4