

SPECIFICATION:



Operating Voltage (Max.):	60 Vdc
Operating Current (Nom.):	10 A
Operating Temperature:	-20°C to 90°C
Insulation Resistance (Min.):	500 MΩ
Contact Resistance (Max.):	5 mΩ

MATERIAL:

Material (Terminal):	brass, nickel plated
Material (Housing):	ABS
Material (Contact Area):	brass, nickel plated

HANDLING:

Terminal:	solder
Packaging:	bulk
PU:	500 piece(s)

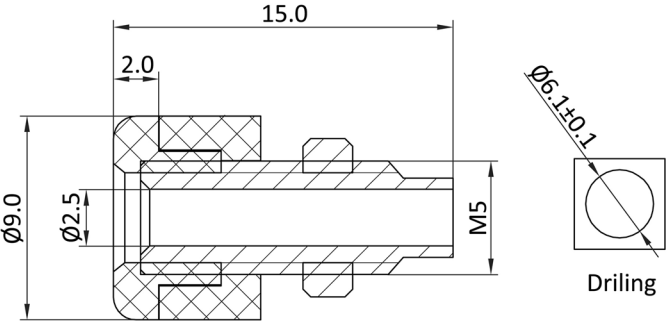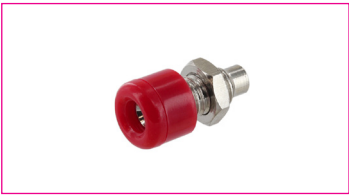

Order Information

Identifier:	Colour:
HOB25	#
HO socket 2.5 mm	SW: black
	RT: red
	BL: blue
	GE: yellow
	GN: green
	WS: white