

Modular Jacks, shielded

SMT



SPECIFICATION:

Current rating:	1.5 A
Insulation resistance:	500 M Ω min.
Contact resistance:	40 m Ω max.
Dielectric voltage:	1000 V AC
Operation temperature:	0 °C to +70 °C

MATERIAL:

Housing:	PBT UL94V-0
Contacts:	Phosphorbronze
Solder pins:	Phosphorbronze
Shield:	Brass

FINISH:

Contacts:	Gold over nickel
Solder pins:	Tin over nickel
Shield:	Nickel plated





HANDLING:

Processing:	Wave soldering
Packing:	Tray

TOLERANCE:

.X	± 0.38
.XX	± 0.25

RoHS
COMPLIANT

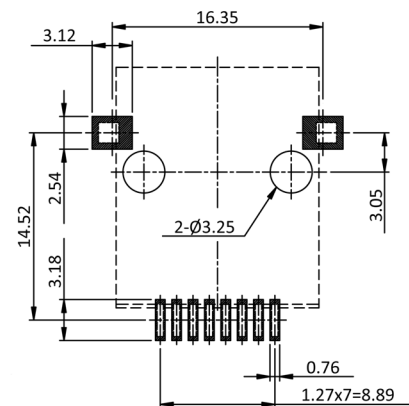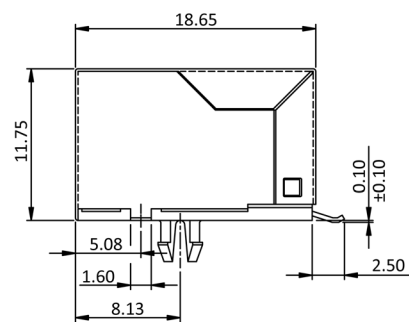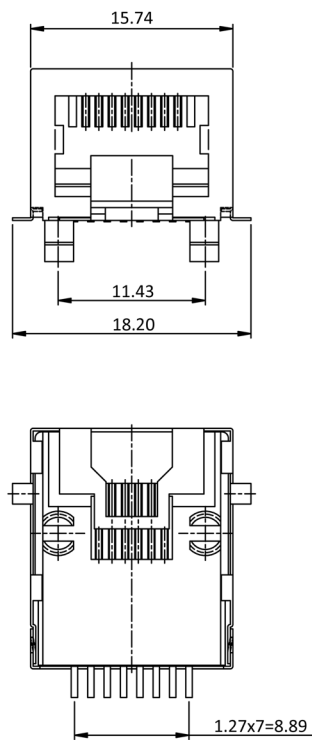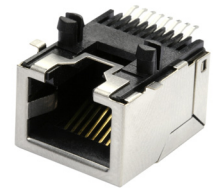

Order-Information

Identifier:

MEB8/8GSMTKS

Modular Jack 8P8C shielded, SMT