

USB Connectors Micro USB 3.0 Sockets

Type B, SMT



SPECIFICATION:

Operating Current (Nom.):	2 A
Operating Temperature:	-55°C to 105°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	30 mΩ
Dielectric Strength:	500 Vac

MATERIAL:


 



Material (Terminal):	copper alloy, tin plated
Material (Insulation):	LCP
Flammability Class:	UL 94 V-0
Material (Contact Area):	copper alloy, gold plated

HANDLING:

Packaging:	taped
------------	-------

TOLERANCE:

.X:	± 0.25
.XX:	± 0.20

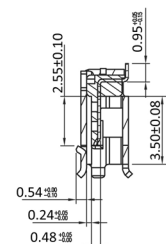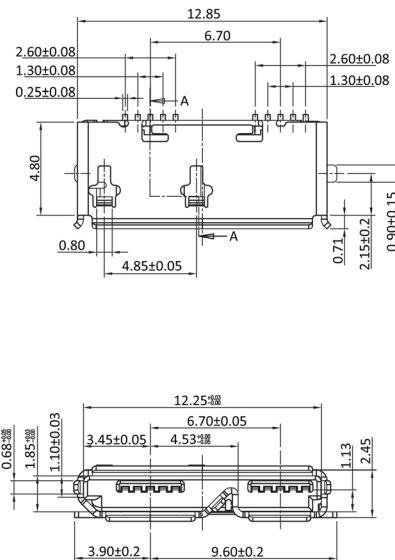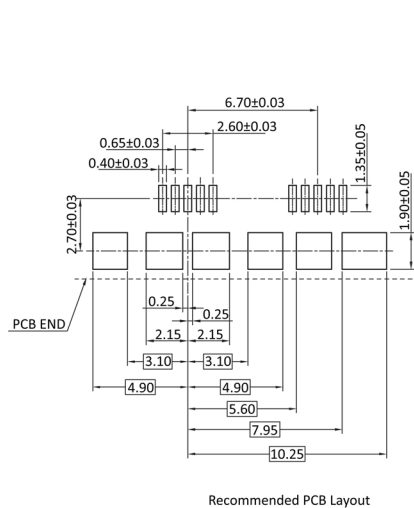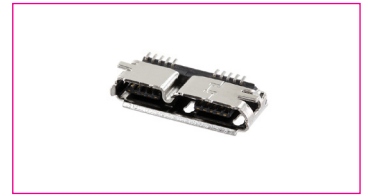

Order Information

Identifier:

MICUBN10BBS

USB 3.0 Socket 10 poles B-Typ SMT