

Sockets Contact Strips Pitch 2.54 mm

Machined Pin Socket Strips, double
row



SPECIFICATION:

Current rating: 3 A
Voltage rating: 60 V
Insulation resistance: 1000 MΩ min.
Contact resistance: 4 mΩ max.
Dielectric voltage: 500 V AC
Operation temperature: -55 °C to +105 °C

MATERIAL:

Housing: PPS UL94V-0
Contacts: Brass, machined CuZn38Pb2
Clip: Beryllium copper

FINISH:

Contacts: Tin plated
Clip: Selective Gold Flash






HANDLING:

Processing: Wave soldering

TOLERANCE:

.X ± 0.25
.XX ± 0.20

RoHS
COMPLIANT

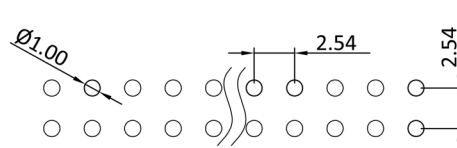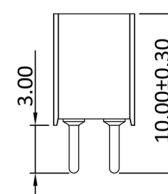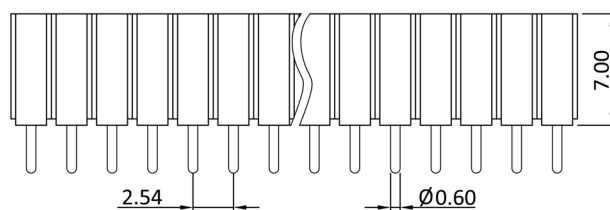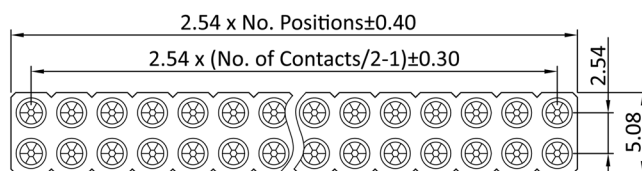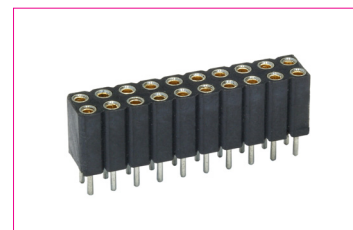

Order-Information

Identifier:

MP70D

No. of contacts:

#

Socket Strip Pitch 2.54 mm double row Height 7.0 mm

4: 2 x 2

6: 2 x 3

8: 2 x 4

:

80: 2 x 40