

Sockets Contact Strips Pitch 2.54 mm

Machined Pin Socket Strips, single row



RoHS
COMPLIANT

SPECIFICATION:

Current rating: 3 A
 Voltage rating: 60 V
 Insulation resistance: 1000 MΩ min.
 Contact resistance: 4 mΩ max.
 Dielectric voltage: 500 V AC
 Operation temperature: -55 °C to +105 °C

MATERIAL:

Housing: PPS UL94V-0
 Contacts: Brass, machined CuZn38Pb2
 Clip: Beryllium copper

FINISH:

 
 



Contacts: Tin plated
 Clip: Selective Gold Flash

HANDLING:

Processing: Wave soldering

TOLERANCE:

.X ± 0.25
 .XX ± 0.20

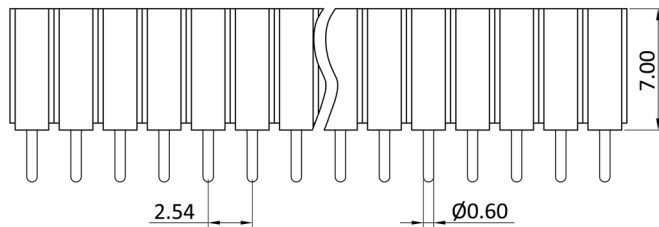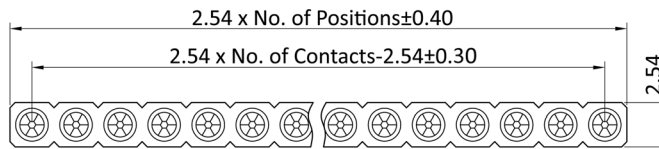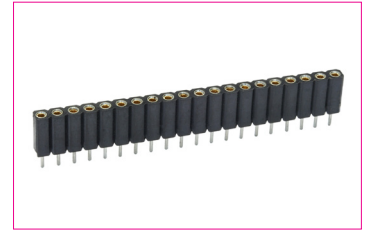

Order-Information

Identifier:

MP70S

No. of contacts:

#

Socket Strip Pitch 2.54 mm single row Height 7.0 mm

2: 1 x 2
 3: 1 x 3
 4: 1 x 4
 :
 40: 1 x 40