

SPECIFICATION:



Operating Voltage (Max.):	125 Vac
Operating Current (Nom.):	1.5 A
Operating Temperature:	-40°C to 85°C
Insulation Resistance (Min.):	500 MΩ
Contact Resistance (Max.):	20 MΩ
Dielectric Strength:	1,000 Vac
AWG (Min.):	AWG 24
AWG (Max.):	AWG 22
Cable Diameter (Max.):	6.5 mm
Conductor Diameter:	1.2 to 1.45 mm (stranded wire)

MATERIAL:








Material (Housing):	polycarbonate
Flammability Class:	UL 94 V-2
Material (Contact Area):	copper alloy, 50 μ" gold plating

HANDLING:

Packaging:	bulk
------------	------

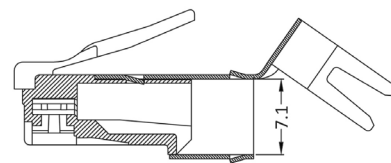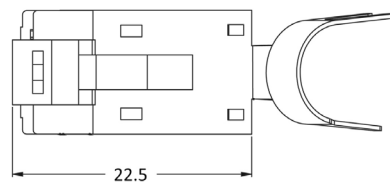

SECTION A-A

   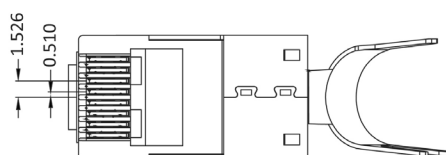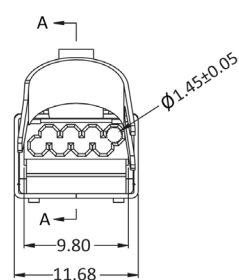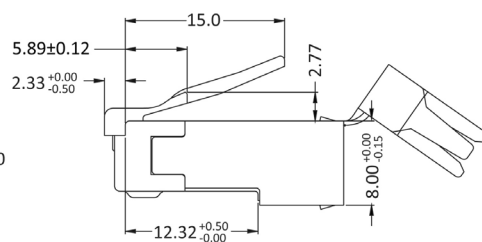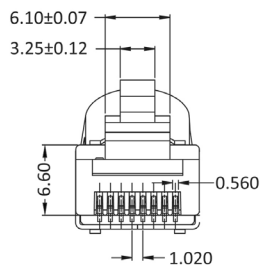

Order Information

Identifier:

MPL88C8R

Modular plug 8P8C Cat.8 shielded, for round cable