

DIN 41651 Flat Cable Connector System IDC Socket Connectors

Pitch 1.27 mm



SPECIFICATION:

Operating Current (Nom.):	1 A
Operating Temperature:	-40°C to 105°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	20 mΩ
Dielectric Strength:	250 Vac

MATERIAL:



Material (Terminal):	copper alloy, gold plated
Material (Housing):	PBT
Flammability Class:	UL 94 V-0
Material (Contact Area):	copper alloy, gold plated

HANDLING:

Packaging:	tray
------------	------

TOLERANCE:

.X:	± 0.25
.XX:	± 0.20

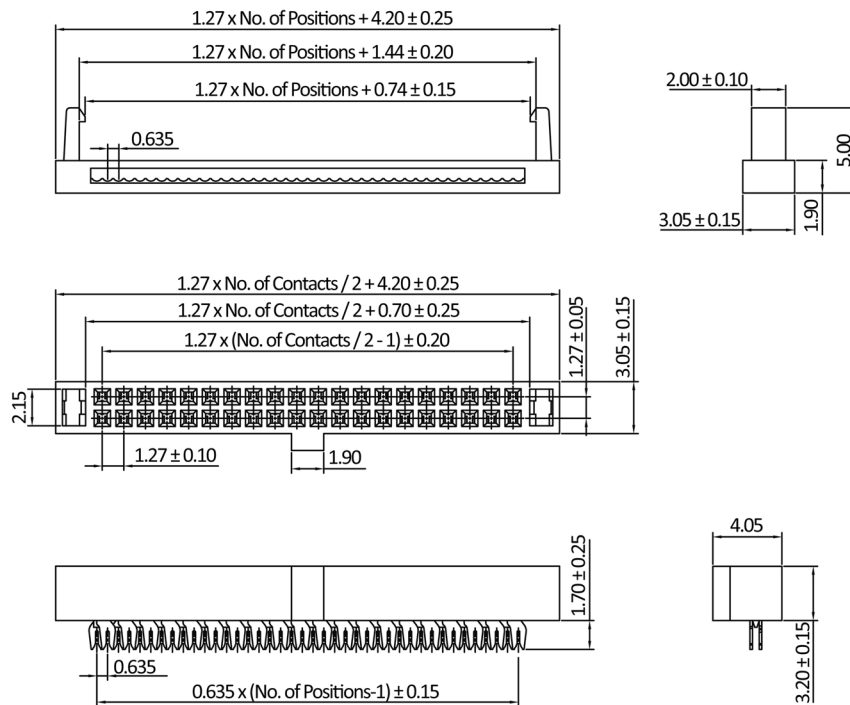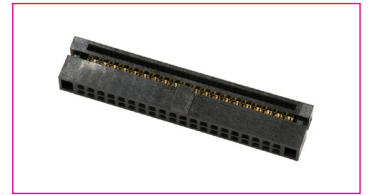

Order Information

Identifier:	No. of Contacts:	Contact Plating:	Version:
PC	#	G	1
IDC socket pitch 1.27 x 1.27 mm	6: 2 x 3 8: 2 x 4 10: 2 x 5 12: 2 x 6 14: 2 x 7 16: 2 x 8 18: 2 x 9 20: 2 x 10 26: 2 x 13 30: 2 x 15 34: 2 x 17 40: 2 x 20 44: 2 x 22 50: 2 x 25	gold plated	with polarization key