

DIN 41651 Flat Cable Connector System IDC Socket Connectors

Polarizing Key



SPECIFICATION:

Operating Temperature:	-25°C to 85°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	15 mΩ
Dielectric Strength:	500 Vac

MATERIAL:




Material (Housing):	PBT
Flammability Class:	UL 94 V-0

HANDLING:


Packaging:	bulk
------------	------

TOLERANCE:

.X:	± 0.20
.XX:	± 0.10

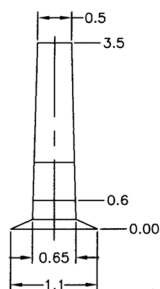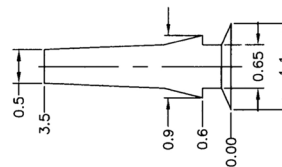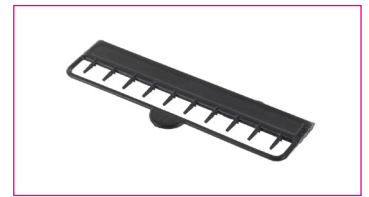

DETAIL: "A"

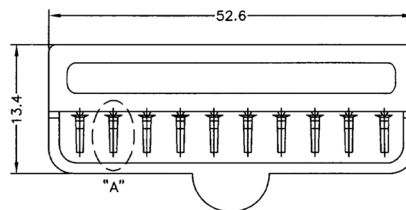

Order Information

Identifier:

PKPV

Polarizing key for pitch 2.54 mm