

**Board-to-Wire Connectors
Pitch 2.54 mm Series CV**

Connectors CV series with wires




SPECIFICATION:

Operating Voltage (Max.):	250 V
Operating Current (Nom.):	3 A
Operating Temperature:	-25°C to 85°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	20 mΩ
Dielectric Strength:	1,000 Vac

MATERIAL:

Material (Terminal):	brass, tin plated
Material (Housing):	nylon 66
Flammability Class:	UL 94 V-2
Material (Contact Area):	brass, tin plated
AWG:	UL1007-24AWG 30 cm

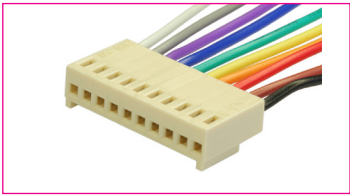


HANDLING:

Packaging:	bulk
------------	------

TOLERANCE:

.X:	± 0.10
.XX:	± 0.05

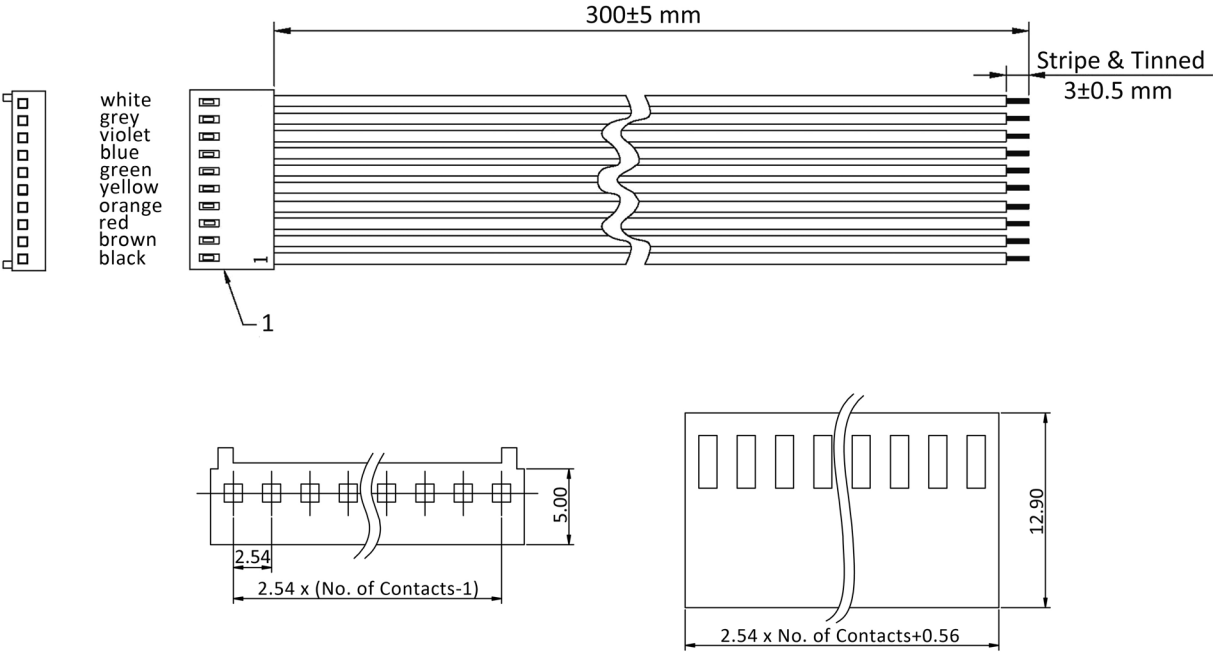

Order Information

Identifier:	No. of Contacts:
PS	#
Connector series CV pitch 2.54 mm with fixed wiring cable	2: 1 x 2
	3: 1 x 3
	4: 1 x 4
	:
	20: 1 x 20