

Pin Headers Pitch 2.0 mm, straight

Single row PBT, length 8.8 mm



SPECIFICATION:

Operating Current (Nom.):	2 A
Operating Temperature:	-40°C to 105°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	20 mΩ
Dielectric Strength:	500 Vac (1 min)

MATERIAL:



Material (Insulation):	PBT
Flammability Class:	UL 94 V-0
Material (Contact Area):	copper alloy, gold plated

HANDLING:



Processing:	wave soldering
Packaging:	bulk

TOLERANCE:

.X:	± 0.25
.XX:	± 0.20

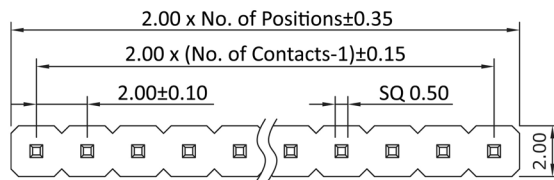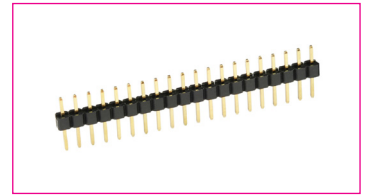

Recommended PCB Layout
(PCB Tolerance ±0.05)

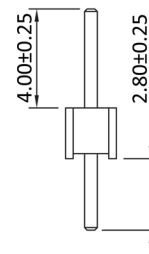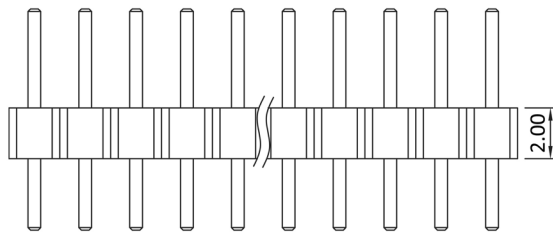

Order Information

Identifier:	No. of Contacts:	Version:	Special:	Pitch:
SL	#	G	1	R2
Pin header pitch 2.0 mm	2: 1 x 2	straight	single row	Pitch 2.0 mm
	3: 1 x 3			
	4: 1 x 4			
	:			
	40: 1 x 40			