

Pin Headers Pitch 2.54 mm, straight

Double row Nylon



SPECIFICATION:

Operating Current (Nom.):	3 A
Operating Temperature:	-40°C to 105°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	20 mΩ
Dielectric Strength:	1,000 Vac

MATERIAL:



Material (Terminal):	copper alloy
Material (Insulation):	nylon 6T
Flammability Class:	UL 94 V-0
Material (Contact Area):	copper alloy, gold plated

HANDLING:

Processing:	wave soldering
Packaging:	bulk

TOLERANCE:

.X:	± 0.35
.XX:	± 0.25

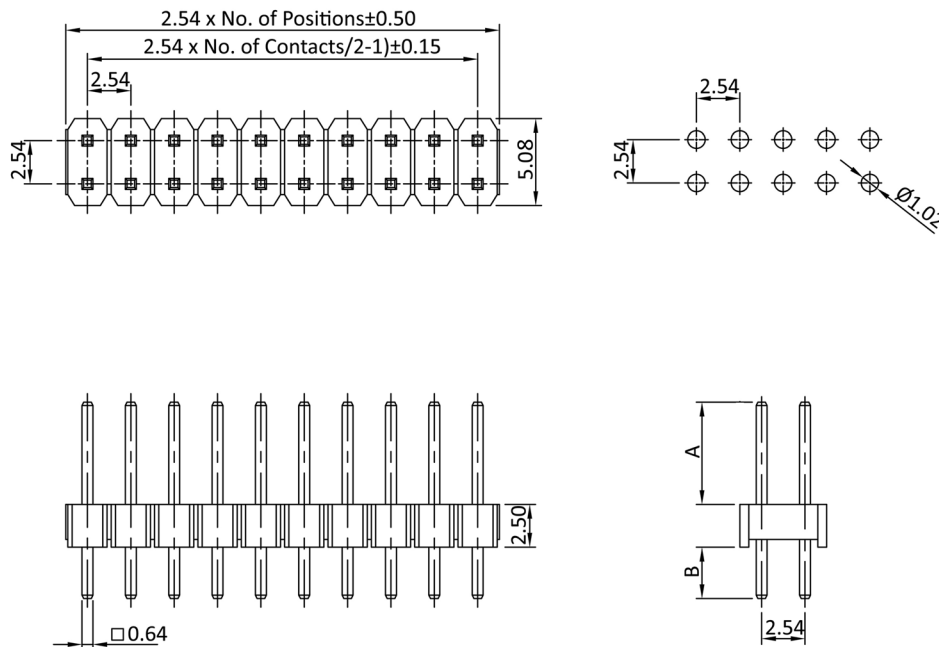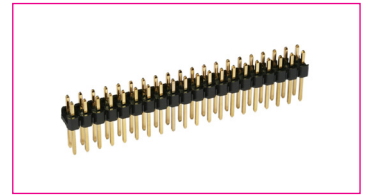

Order Information

Identifier:	No. of Contacts:	Contact Plating:	Length:
SLSD	#	#	#
Pin header pitch 2.54 mm double row straight	4: 2 x 2 6: 2 x 3 8: 2 x 4 : 80: 2 x 40	G: gold plated * A: 5 μ" gold B: 10 μ" gold D: 30 μ" gold S: selective gold plated	A: A=6.1 B=3.0 * E: A=8.3 B=3.0 * F: A=12.3 B=3.0 * X: Special dimensions also available

* = Standard