

D-Sub PCB angled Euro Standard

Male Connectors with Rivet UNC 4/40



SPECIFICATION:

Current rating: 1.5 A
Insulation resistance: 1000 MΩ min.
Contact resistance: 20 mΩ max.
Dielectric voltage: 500 V AC
Operation temperature: -40 °C to +105 °C

MATERIAL:

Insulator: PBT black UL94V-0
Shell: Steel
Pins: Copper alloy

FINISH:

Contacts: Selective gold flash
Shell: Nickel plated



HANDLING:

Processing: Wave soldering
Packing: Tray

TOLERANCE:

.X ± 0.30
.XX ± 0.20

RoHS
COMPLIANT

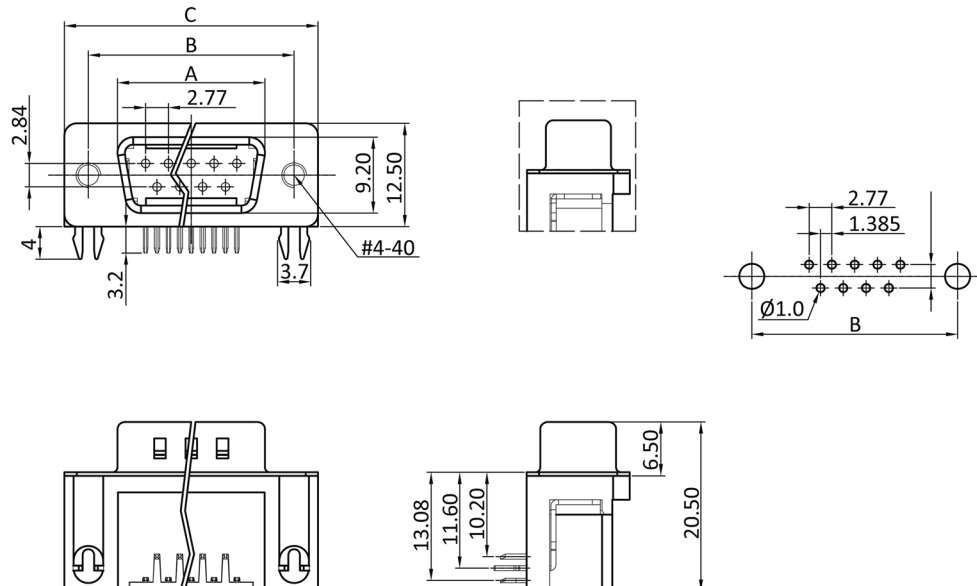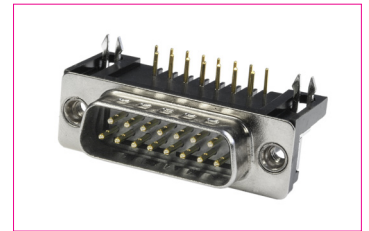

Dimensions

No. of contacts:	A:	B:	C:
9	30.81	16.92	24.99
15	26.50	33.32	39.14
25	40.00	47.04	53.04
37	56.50	63.50	69.32

Order-Information

Identifier:	No. of contacts:	Version:	Special:	Locking:
ST	#	WB	9	G
D-Sub Male with Solder Pins	9: 9 pin 15: 15 pin 25: 25 pin 37: 37 pin	WB: angled	9: Euro standard	G: with threaded holes