

USB Connectors USB 2.0 Sockets Type B

PCB, vertical



SPECIFICATION:

Operating Voltage (Max.):	30 V
Operating Current (Nom.):	1.5 A
Operating Temperature:	-25°C to 80°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	30 mΩ
Dielectric Strength:	500 Vac

MATERIAL:


Material (Terminal):	copper alloy, tin plated
Material (Housing):	brass, nickel plated
Flammability Class:	UL 94 V-0
Material (Insulation):	PBT
Material (Contact Area):	copper alloy, gold plated

HANDLING:

Packaging:	tray
------------	------

TOLERANCE:

.X:	± 0.25
.XX:	± 0.20

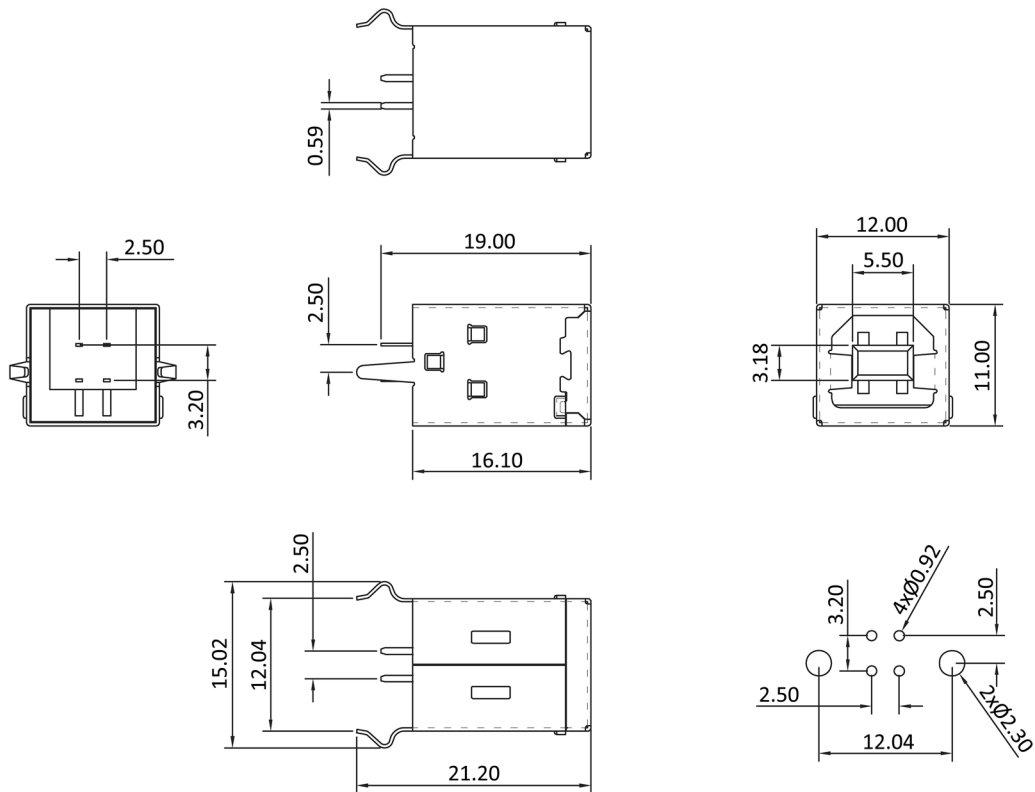

Order Information

Identifier:

UBU1BSII

Socket type B vertical