

DIN 41651 Flat Cable Connector System Box Headers with Locking

Pitch 2.54 mm, IDC, long latches



SPECIFICATION:

Operating Current (Nom.):	3 A
Operating Temperature:	-55°C to 105°C
Insulation Resistance (Min.):	5000 MΩ
Contact Resistance (Max.):	30 mΩ
Dielectric Strength:	1,000 Vac

MATERIAL:


 



Material (Housing):	PBT
Flammability Class:	UL 94 V-0
Material (Contact Area):	copper alloy, gold plated

HANDLING:

Packaging:	tray
------------	------

TOLERANCE:

.X:	± 0.30
.XX:	± 0.20

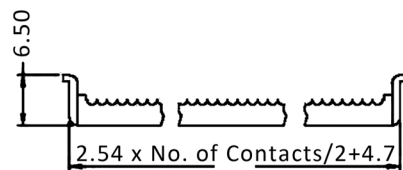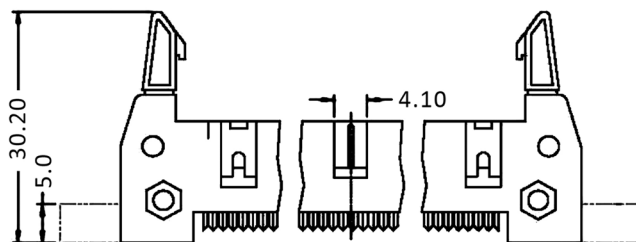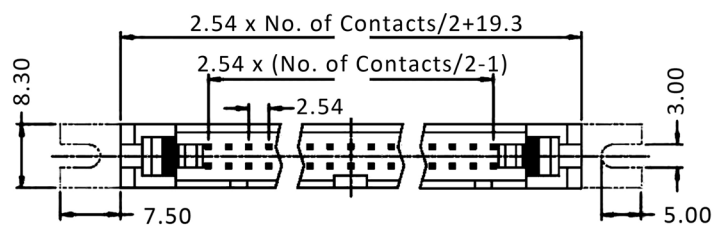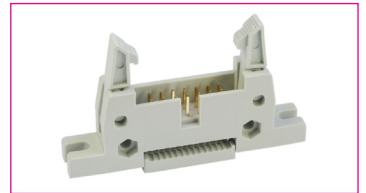

Order Information

Identifier:	No. of Contacts:	Version:	Locking:
WS	#	SK	VL
Box header with flange pitch 2.54 mm	10: 2 x 5	IDC	long latches
	14: 2 x 7		
	16: 2 x 8		
	20: 2 x 10		
	24: 2 x 12		
	26: 2 x 13		
	30: 2 x 15		
	34: 2 x 17		
	40: 2 x 20		
	50: 2 x 25		
	60: 2 x 30		