



Einhell

EXPERT

POWER X-CHANGE

Cordless Pressure Washer

HYPRESSO 18/24-1

Item No.: 4140135

Ident No.: 21012

Bar Code: 4006825672077

The Einhell HYPRESSO 18/24-1 cordless pressure washer gun enables cable-free flexibility for cleaning and watering. It is part of the Power X-Change family. The cordless medium pressure washer works at pressures of up to 24 bar and a maximum flow rate of 240 litres/hour. The spray gun is equipped with a 4-way adjustable nozzle (narrow, wide, rotation and spray jets). The set includes two extension lances, a foam spray bottle, a PET bottle adapter, a 5 m suction hose with water filter for using water from buckets, ponds, etc., a water splash guard for the battery and a mesh bag for storage. Comes without battery or charger.

Features & Benefits

- Member of the Power X-Change family, 1 x 18 V battery required
- Lightweight, easy-to-handle, and compact for convenient cleaning
- Quick cleaning of lightly soiled surfaces
- Multifunctional nozzle with 4-position adjustable spray jet
- Wide range of applications, e.g. for irrigation and cleaning
- Integrated rotary nozzle for thorough cleaning
- ECO mode for longer battery life
- Comfortable handling thanks to ergonomic design with Softgrip inserts
- Includes 2x spray lance extensions
- Foam spray bottle for the use of cleaning agents
- 5 m suction hose for extracting water from buckets, lakes, ponds etc.
- Includes water filter to protect the pump
- Includes mesh bag for storing extensive accessories
- Includes bottle adapter for use with PET bottles
- Includes protective cover for battery
- Comes without battery or charger (sold separately)




Technical Data

- Permissible pressure	24 bar
- Delivery rate	240 L/h
- Max. water temperature	40 °C
- Max. inlet water pressure	5 bar

Logistic Data

- Product weight (kg)	2.1
- Gross weight (kg)	3.5
- Dimensions single packaging	380 x 300 x 130 mm
- Pieces per export carton	4 Pieces
- Gross weight of export carton	14.6 kg
- Dimensions export carton	615 x 410 x 280 mm
- Container quantity (20"/40"/40"HC)	1428 2856 3672

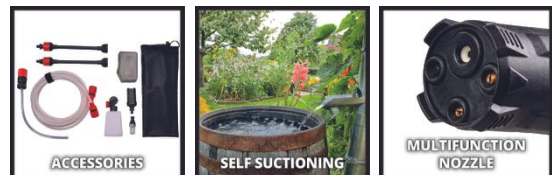

Available as special accessories



4-6 Ah Multi-Ah Power X-Change Plus Battery
Item No.: 4511502
Bar Code: 4006825644210



4,0 Ah Power X-Change Battery
Item No.: 4511396
Bar Code: 4006825610376
Einhell Accessory



Power X-Fastcharger 4A Charger
Item No.: 4512103
Bar Code: 4006825650228
Einhell Accessory



18V 3,0 Ah Power-X-Change 1 Battery
Item No.: 4511341
Bar Code: 4006825590593
Einhell Accessory



2x 4,0Ah & Twincharger Kit 1 PXC-Starter-Kit
Item No.: 4512112
Bar Code: 4006825655766
Einhell Accessory



5,2Ah & 4A Fastcharger PXC-Starter-Kit
Item No.: 4512114
Bar Code: 4006825656787
Einhell Accessory



18V 5-8Ah Multi-Ah PXC Plus Battery
Item No.: 4511600
Bar Code: 4006825665055
Einhell Accessory



PXC Battery Protector PXC-Battery Accessory
Item No.: 4140151
Bar Code: 4006825670844
Einhell Accessory



18V 2,0Ah PXC Starter Kit PXC-Starter-Kit
Item No.: 4512040
Bar Code: 4006825613681
Einhell Accessory



18V 4,0Ah PXC Starter Kit B1 PXC-Starter-Kit
Item No.: 4512042
Bar Code: 4006825613704
Einhell Accessory



18V 2,5Ah PXC Starter Kit PXC-Starter-Kit
Item No.: 4512097
Bar Code: 4006825646962
Einhell Accessory



2x2 Power X-Quattrocharger 4A Charger
Item No.: 4512102
Bar Code: 4006825649536
Einhell Accessory



Power X-Twincharger 3A Charger
Item No.: 4512069
Bar Code: 4006825629729
Einhell Accessory



Power X-Car Charger 3A Charger
Item No.: 4512113
Bar Code: 4006825655377
Einhell Accessory



2x 18V 5,2Ah PXC-Twinpack Battery
Item No.: 4511526
Bar Code: 4006825656695
Einhell Accessory



3,0 Ah Power X-Change Plus Battery
Item No.: 4511501
Bar Code: 4006825644197
Einhell Accessory



5,2 Ah Power X-Change Plus Battery
Item No.: 4511437
Bar Code: 4006825616606
Einhell Accessory



18V 4,0Ah Power-X-Change Plus Battery
Item No.: 4511553
Bar Code: 4006825660869
Einhell Accessory



2,0 Ah Power X-Change Battery
Item No.: 4511395
Bar Code: 4006825610369
Einhell Accessory



2x18V 4,0Ah PXC-Twinpack CB B1 Battery
Item No.: 4511489
Bar Code: 4006825638578

Battery-Running-Times

One Battery for All	 cleaning ¹ (min.)	 cleaning ² (min.)
1.5 Ah	10	6
2.0 Ah	13	7
2.5 Ah	15	8
3.0 Ah	20	11
4.0 Ah	27	15
5.2 Ah	35	18
6.0 Ah	45	23
8.0 Ah	55	30

Test setup:

- 1) Step 1
- 2) Step 2