

D-Sub Metalized cover, Top, with Rubber Grommets

TECHNICAL SPECIFICATIONS


Material:	UL Recognised Plastic Material		
Plating:	Nickel over Copper		
Operating Temperature:	-40°C to +120°C		
Cable Entry:	Top Entry		
Thumbscrews:	UNC 4-40		
Cable O.D.:	Size 9:	Up to 8,1mm	
	Size 15:	Up to 8,1mm	
	Size 25:	Up to 11,4mm	
	Size 37:	Up to 16,5mm	
	Size 50:	Up to 16,5mm	

Features:


- Available in sizes 9-15-25-37-50
- Re-openable
- Strain Relief / Compression Insert manufactured in Thermoplastic compound.



Compression Inserts - Inner Diameters:

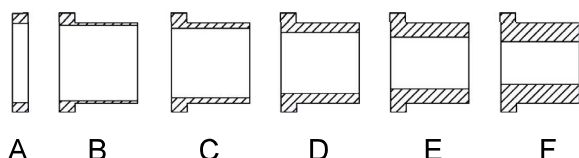

Size	A	B	C	D	E	F
9-15	8,10	8,00	7,25	6,50	5,30	-
25	11,40	10,40	9,40	7,60	5,80	-
37-50	16,50	15,75	14,50	12,70	10,80	8,90

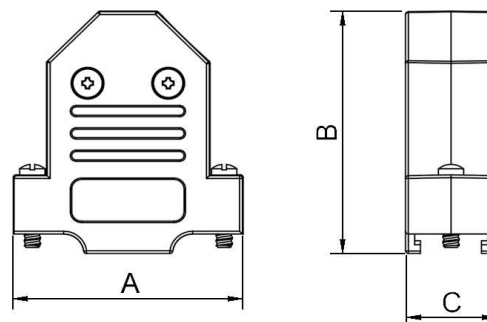

Size DTNT-M	Dim A	Dim B	Dim C
9-way	31,3	40,0	16,3
15-way	39,1	43,5	16,3
25-way	53,1	47,7	16,3
37-way	69,3	53,9	16,3
50-way	67,2	50,8	19,6

Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	1060-0105-01	DTNT09-M-K
15-way	1060-0105-02	DTNT15-M-K
25-way	1060-0105-03	DTNT25-M-K
37-way	1060-0105-04	DTNT37-M-K
50-way	1060-0105-05	DTNT50-M-K

Size:	P/N - BULK:	Product Code:
9-way	1061-0105-01	DTNT09-M
15-way	1061-0105-02	DTNT15-M
25-way	1061-0105-03	DTNT25-M
37-way	1061-0105-04	DTNT37-M
50-way	1061-0105-05	DTNT50-M



Encitech AB
Rörkullsvägen 4
SE-302 41 HALMSTAD, Sweden

Tel.: +46-(0)35-15 13 90
Fax: +46-(0)35-15 13 99

www.encitech.com