

D-Sub

TECHNICAL SPECIFICATIONS


Materials:

Unshielded Hood: UL-recognised plastic material
 Colour: Black

Shielded Hood: UL-recognised plastic material
 Plating: Nickel over Copper

Operating Temperature: -30°C to +110°C

Jackscrews: UNC 4-40 (Standard)

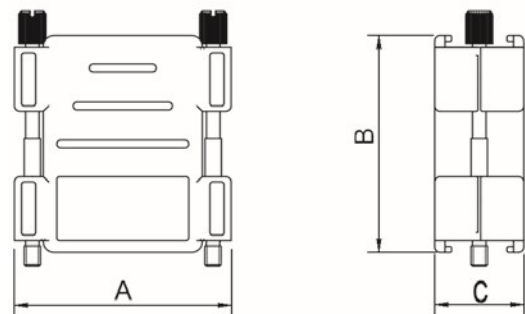

Size DA	Dim A	Dim B	Dim C
9-way	31,6	40,0	16,4
15-way	39,9	40,0	16,4
25-way	53,6	40,0	16,4

Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	1511-0101-01	DPAK-M-09-K
15-way	1511-0101-02	DPAK-M-15-K
25-way	1511-0101-03	DPAK-M-25-K

