


D-Sub Connectors

DD-Series – Angled D Connectors, 9.4mm


Material Specification:

Insulator:	Glass filled Polyester, Black UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contacts pins:	Machined pins
Contact pin material:	Copper Alloy
Contact Plating:	Gold over Nickel as standard Class 3, 100 inserts min. Other class on request


7.2mm footprint (Angled, RAM) available on request.

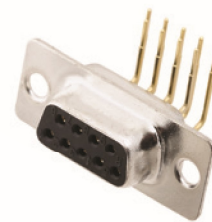

Plug connector

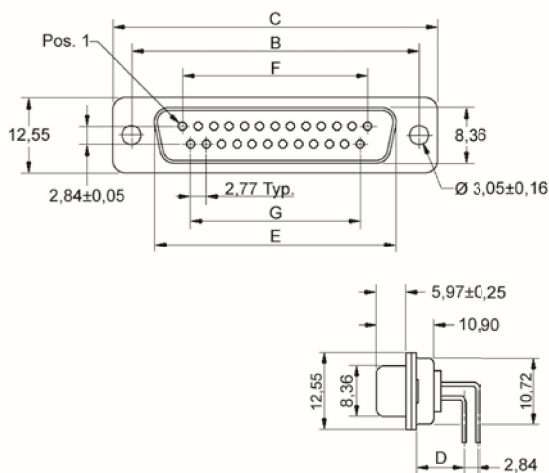

Socket connector

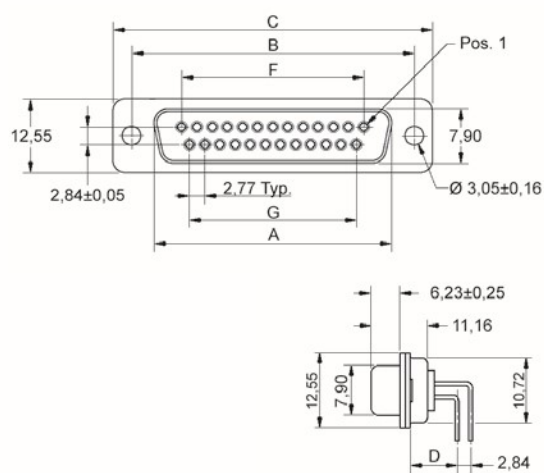


Size	A	B	C	D: (RBM)	E	F	G
9	16,92	24,99	30,81	9,4	16,33	11,08	8,31
15	25,25	33,32	39,14	9,4	24,66	19,39	16,62
25	38,96	47,04	53,04	9,4	38,38	33,24	30,47
37	55,25	63,50	69,32	9,4	54,84	49,86	47,09
50*	Available on request						

Order Codes - Standard Type - with Ø 3.05mm Through Hole

Option X (Standard)

Ø 3.05mm Holes

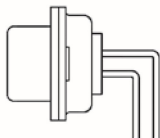

Plug Connector

09	2103-2200-01	DD09-MTBG-RBM
15	2103-2200-02	DD15-MTBG-RBM
25	2103-2200-03	DD25-MTBG-RBM
37	2103-2200-04	DD37-MTBG-RBM
50	2103-2200-05	DD50-MTBG-RBM

Socket Connector

09	2103-2200-11	DD09-FTBG-RBM
15	2103-2200-12	DD15-FTBG-RBM
25	2103-2200-13	DD25-FTBG-RBM
37	2103-2200-14	DD37-FTBG-RBM
50	2103-2200-15	DD50-FTBG-RBM



Encitech AB
Rörkullsvägen 4
SE-302 41 HALMSTAD, Sweden

Tel: +46-(0)35-15 13 90
e-mail: connectors@encitech.com

www.encitech.com