

D-Sub Plastic cover, Black, Top Entry, short jackscrews



TECHNICAL SPECIFICATIONS

Material:	UL Recognised Plastic Material	
Operating Temperature:	-55°C to +110°C	
Cable Entry:	Top	
Thumbscrews:	UNC 4-40	
Cable O.D:	9-way	Up to 7,0mm
	15-way	Up to 10,0mm
	25-way	Up to 11,0mm
	37-way	Up to 13,8mm
	50-way	Up to 14,0mm
Colour:	Black	



Features:

- Available in sizes 9-15-25-37-50
- Suitable for any common Sub-D connector
- Short Jackscrews
- Re-openable
- Available in two colours: Black & Light Grey
- Also available in Metalized Version

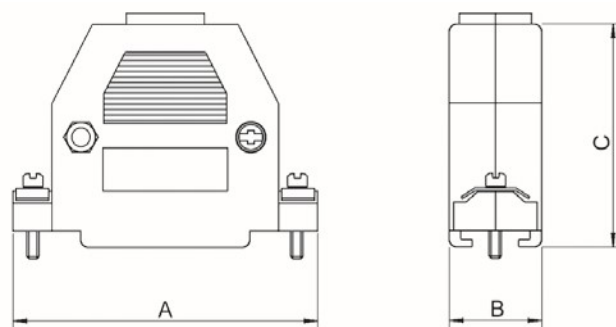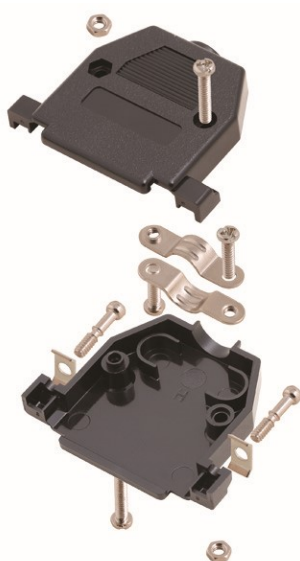

Size CCOV	A	B	C
9-way	31,0	16,0	40,2
15-way	39,6	17,4	38,0
25-way	55,0	16,5	44,5
37-way	69,0	24,0	52,5
50-way	69,5	19,5	44,5

Ordering information:

Size:	P/N - Kitted:	Product Code - BLACK
9-way	2360-0102-01	CCOV 9-SC-BK
15-way	2360-0102-02	CCOV15-SC-BK
25-way	2360-0102-03	CCOV25-SC-BK
37-way	2360-0102-04	CCOV37-SC-BK
50-way	2360-0102-05	CCOV50-SC-BK



Encitech AB
Rörkullsvägen 4
SE-302 41 HALMSTAD, Sweden

Tel: +46-(0)35-15 13 90
e-mail: connectors@encitech.com

www.encitech.com