


D-Sub Full Metal cover, Top entry, Short Jackscrews




TECHNICAL SPECIFICATIONS

Material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	Top Entry
Cable O.D:	Up to 16mm
Jackscrews:	UNC 4-40

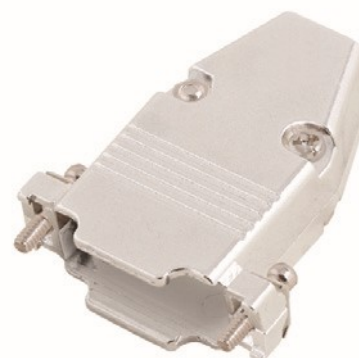

Features:

- Available in sizes 9, 15, 25, 37 and 50
- Suitable for any common Sub-D connector
- Re-Openable
- Available also with Long Jackscrews (MEL)

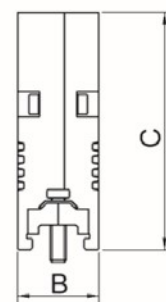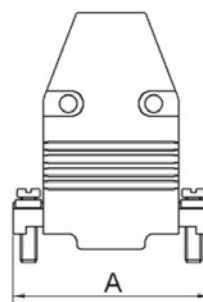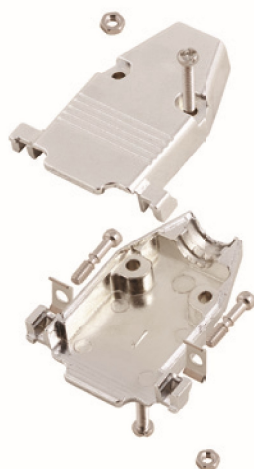

Size CCOV	Dim A	Dim B	Dim C
9-way	31,4	16,2	48,3
15-way	40,2	16,2	48,3
25-way	53,0	16,2	48,3
37-way	69,2	16,2	48,3
50-way	67,0	18,4	48,3

Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	2360-0106-01	CCOV 9-ME
15-way	2360-0106-02	CCOV15-ME
25-way	2360-0106-03	CCOV25-ME
37-way	2360-0106-04	CCOV37-ME
50-way	2360-0106-05	CCOV50-ME

