

## D-Sub

## TECHNICAL SPECIFICATIONS

## Materials:

Plastic Hood: Polyamid - UL-recognised

Operating Temperature: -55°C to +110°C


Thumbscrews: UNC 4-40 (Standard)




## Features:

- Suitable for sizes 15, 25
- Screw together Hood halves
- Re-openable
- Also available in Shielded version

DAPK 15

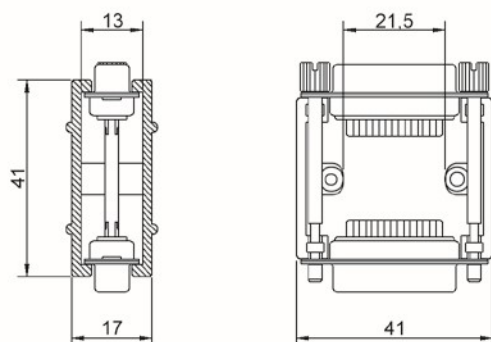

DAPK 25

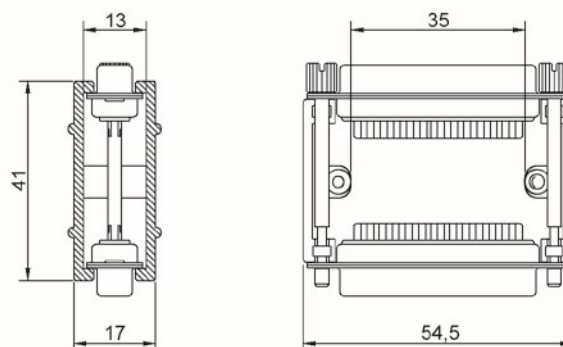

## Ordering information:

| Size:  | P/N - Kitted: | Product Code: |
|--------|---------------|---------------|
| 15-way | 6211-0100-32  | DAPK15-JS     |
| 25-way | 6211-0100-33  | DAPK25-JS     |

## Note:

All adapters are delivered with 2 long jackscrews in standard versions as seen in above drawings and ordering information.



**Encitech AB**  
Rörkullsvägen 4  
SE-302 41 HALMSTAD, Sweden

Tel: +46-(0)35-15 13 90  
e-mail: connectors@encitech.com

**www.encitech.com**