

D-Sub


TECHNICAL SPECIFICATIONS

Materials:

Plastic Hood: Polyamid - UL-recognised

Operating Temperature: -55°C to +110°C


Thumbscrews: UNC 4-40 (Standard)

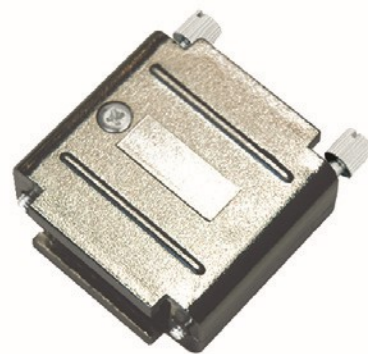


Features:

- Suitable for sizes 15, 25
- Screw together Hood halves
- Re-openable
- Also available in Shielded version

DAPK 15

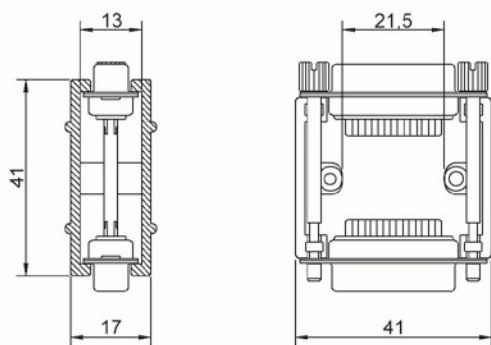

DAPK 25

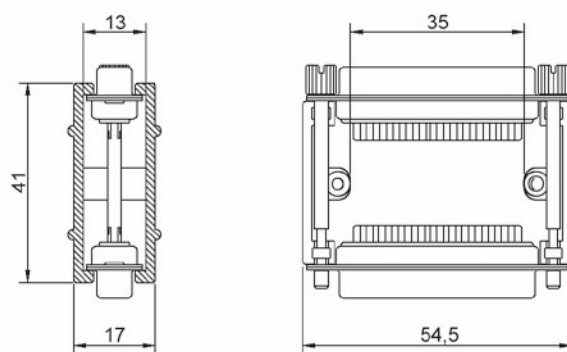

Ordering information:

Size:	P/N - Kitted:	Product Code:
15-way	6211-0100-42	DAPK15-JS/MET
25-way	6211-0100-43	DAPK25-JS/MET

Note:

All adapters are delivered with 2 long jackscrews in standard versions as seen in above drawings and ordering information.



Encitech AB
Rörkullsvägen 4
SE-302 41 HALMSTAD, Sweden

Tel: +46-(0)35-15 13 90
e-mail: connectors@encitech.com

www.encitech.com