

## D-Sub Plastic Cover, Black, with top cable entry


## TECHNICAL SPECIFICATIONS

|                        |                                              |              |
|------------------------|----------------------------------------------|--------------|
| Material:              | Polyamid, UL-recognised                      |              |
| Operating Temperature: | -55°C to +110°C                              |              |
| Cable Entry:           | Top                                          |              |
| Thumbscrews:           | UNC 4-40 (Standard)<br>M2,5 or M3 on request |              |
| Cable O.D:             | 9-way                                        | Up to 8mm    |
|                        | 15-way                                       | Up to 11,7mm |
|                        | 25-way                                       | Up to 11,7mm |
|                        | 37-way                                       | Up to 11,7mm |
|                        | 50-way                                       | Up to 11,7mm |
| Colour:                | Black                                        |              |



## Features:

- Available in sizes 9-15-25-37-50-way
- Suitable for any common Sub-D connector
- Quick-snap locking system
- Company logo can be moulded on request

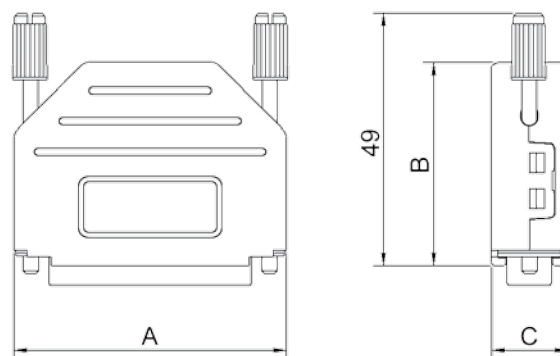

## Accessory:

- Small Rubber grommet (size 9 only)  
6844-0102-01
- Large Rubber grommet (size 15-25-37-50)  
6844-0103-01



| Size   | Dim A | Dim B | Dim C |
|--------|-------|-------|-------|
| 9-way  | 31,5  | 34,0  | 15,0  |
| 15-way | 40,0  | 34,0  | 15,0  |
| 25-way | 53,5  | 34,0  | 15,0  |
| 37-way | 70,0  | 40,0  | 15,0  |
| 50-way | 67,5  | 40,0  | 15,0  |

Ordering information: *Standard - Black*

| Size:  | P/N - Kitted: | Product Code: |
|--------|---------------|---------------|
| 9-way  | 6260-0101-01  | DPPK09-BK-K   |
| 15-way | 6260-0101-02  | DPPK15-BK-K   |
| 25-way | 6260-0101-03  | DPPK25-BK-K   |
| 37-way | 6260-0101-04  | DPPK37-BK-K   |
| 50-way | 6260-0101-05  | DPPK50-BK-K   |

| Size:  | P/N - BULK:  | Product Code: |
|--------|--------------|---------------|
| 9-way  | 6261-0101-01 | DPPK09-BK     |
| 15-way | 6261-0101-02 | DPPK15-BK     |
| 25-way | 6261-0101-03 | DPPK25-BK     |
| 37-way | 6261-0101-04 | DPPK37-BK     |
| 50-way | 6261-0101-05 | DPPK50-BK     |