



D-Sub Plastic Cover, Top or Side cable entry + Long jackscrews

TECHNICAL SPECIFICATIONS


Material:	Polyamid, UL-recognised
Operating Temperature:	-55°C to +110°C
Cable Entry:	Side and Top
Thumbscrews:	Long and Short UNC 4-40 (Standard) M2,5 or M3 on request
Cable O.D:	9-way Up to 11,5mm 15-way Up to 11,5mm 25-way Up to 11,5mm
Colour:	Black

Features:

- Plastic cover Top or Side
- Available in sizes 9-15-25
- Suitable for any common Sub-D connector
- Quick-snap locking system
- Re-openable
- Company logo available upon request
- Jackscrews 9-way
1 long jackscrew
- Jackscrews 15- & 25-way
2 long jackscrews
1 short jackscrew

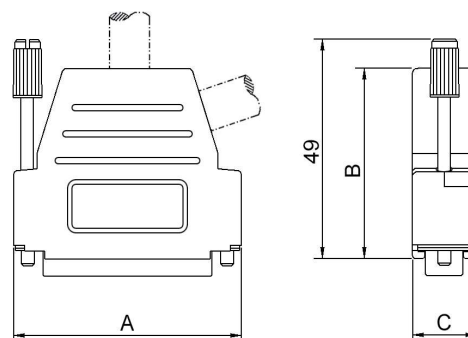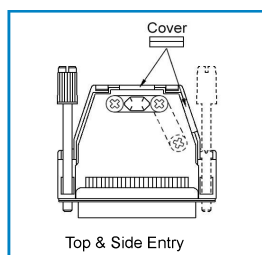

Plastic grommet set

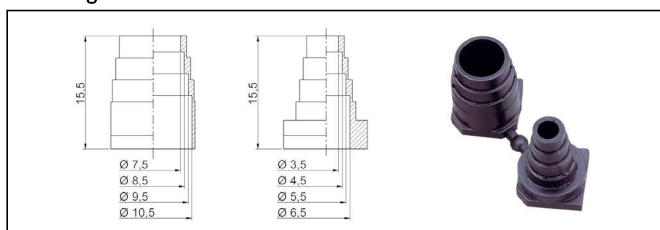

Size DSSK-P	Dim A	Dim B	Dim C
9-way	31,5	40,0	15,0
15-way	40,0	40,0	15,0
25-way	53,5	43,0	15,0

Ordering information:

Size:	P/N - Kittet:	Product Code:
9-way	6260-0107-01	DSSK-P-09-L-K
15-way	6260-0107-02	DSSK-P-15-L-K
25-way	6260-0107-03	DSSK-P-25-L-K

Size:	P/N - BULK:	Product Code:
9-way	6261-0107-01	DSSK-P-09-L
15-way	6261-0107-02	DSSK-P-15-L
25-way	6261-0107-03	DSSK-P-25-L



Encitech AB
Rörkullsvägen 4
SE-302 41 HALMSTAD, Sweden

Tel.: +46-(0)35-15 13 90
Fax: +46-(0)35-15 13 99

www.encitech.com