


D-Sub Plastic cover, Top or Side entry + Grommet set



TECHNICAL SPECIFICATIONS

Material:	Polyamid, UL-recognised	
Operating Temperature:	-55°C to +110°C	
Cable Entry:	Side and Top	
Thumbscrews:	UNC 4-40 (Standard) M2,5 or M3 on request	
Cable O.D:	9-way	Up to 11,5mm
	15-way	Up to 11,5mm
	25-way	Up to 11,5mm
	37-way	Up to 11,5mm
Colour:	Black	

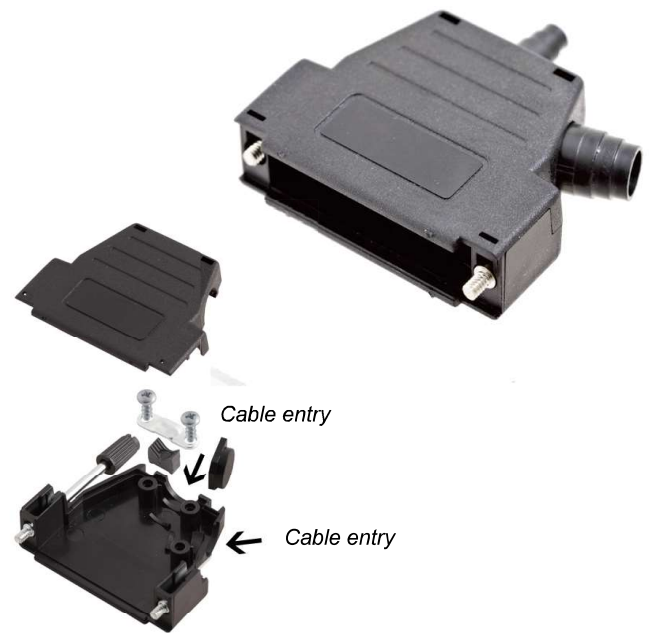


Features:

- Plastic cover including 2-piece plastic grommet
- 37-way Side entry only
- Short and Long jackscrew included
- Quick-snap locking system
- Re-openable
- Company logo available on request

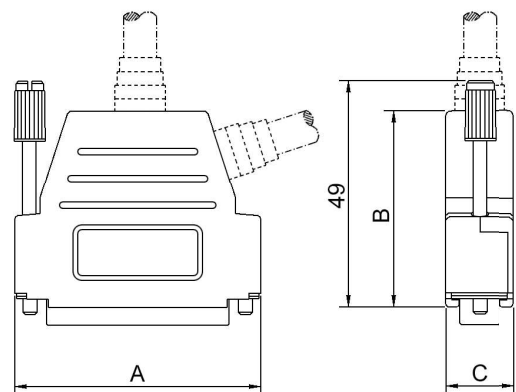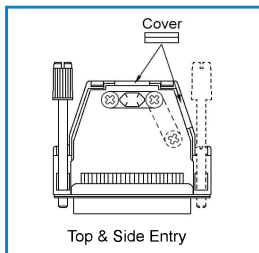

Plastic grommet set

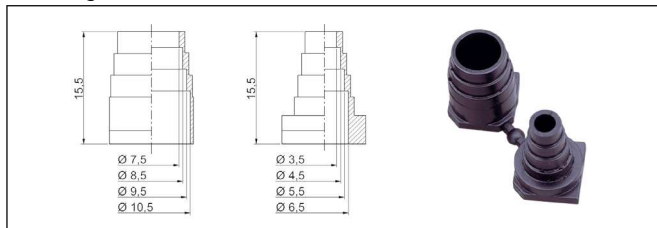

Size DSSK-P	Dim A	Dim B	Dim C
9-way	31,5	40,0	15,0
15-way	40,0	40,0	15,0
25-way	53,5	43,0	15,0
37-way	71,3	40,0	15,0

Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	6260-0107-41	DSSK-P-09-L+G-K
15-way	6260-0107-42	DSSK-P-15-L+G-K
25-way	6260-0107-43	DSSK-P-25-L+G-K
37-way	6260-0107-44	DSSK-P-37-S+G-K

Size:	P/N - BULK:	Product Code:
9-way	6261-0107-41	DSSK-P-09-L+G
15-way	6261-0107-42	DSSK-P-15-L+G
25-way	6261-0107-43	DSSK-P-25-L+G
37-way	6261-0107-44	DSSK-P-37-S+G

