


TECHNICAL SPECIFICATIONS

D-Sub Hood:

Material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	Top Entry
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D.:	Up to 11,5mm (Size 9-37) Up to 17mm (Size 50)

Male D-Sub Solder Cup:

Insulator:	PBT, Black, UL94 V-0
Shell:	Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed Pins	Class 3, 100 inserts min.
Machined Contact Pins:	Class 1, 500 inserts min.
Contact Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	1000V for 1 minute
Insulator resistance:	1000MΩ min.

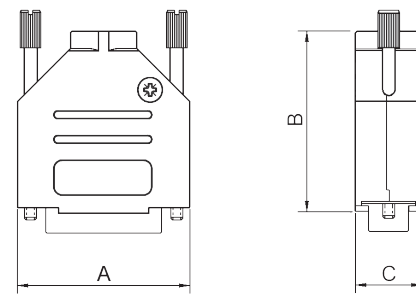

D-Sub-Hood

Features:

- Available in sizes 9-15-25-37-50
- Packed in Kit with MALE D-connector
- Class 3 or Class 1 connector as standard options
- Re-openable
- Full Metal Jackscrew as standard.

Size DTZK	Dim A	Dim B	Dim C
9-way	31,0	39,5	15,0
15-way	39,5	41,5	15,0
25-way	53,5	48,5	15,0
37-way	71,0	53,0	15,0
50-way	67,5	54,0	18,7

Ordering information:**Class 3 Sub-D Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
9-way	6355-0002-01	DTZK09-DBP-K
15-way	6355-0002-02	DTZK15-DBP-K
25-way	6355-0002-03	DTZK25-DBP-K
37-way	6355-0002-04	DTZK37-DBP-K
50-way	6355-0002-05	DTZK50-DBP-K

Ordering information:**Class 1 Sub-D Connector Kits (500 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
9-way	6355-0002-21	DTZK09-DMP-K
15-way	6355-0002-22	DTZK15-DMP-K
25-way	6355-0002-23	DTZK25-DMP-K
37-way	6355-0002-24	DTZK37-DMP-K
50-way	6355-0002-25	DTZK50-DMP-K