

TECHNICAL SPECIFICATIONS

D-Sub Hood:

Material:	UL 94 V-0 Plastic Material
Operating Temperature:	-55°C to +110°C
Cable Entry:	Side
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D.:	Up to 11,5mm
Colour:	Black



Female Sub-D Connector:

Insulator:	PBT, Black, UL94 V-0
Shell:	Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed Pins	Class 3, 100 inserts min.
Machined Contact Pins:	Class 1, 500 inserts min.
Contact Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	1000V for 1 minute
Insulator resistance:	1000MΩ min.

Features:

- Available in sizes 9-15-25-37
- Suitable for any common Sub-D connector
- Strain relief inserts ensure a secure termination
- Re-openable

Grommet Sizes D45PK-P:

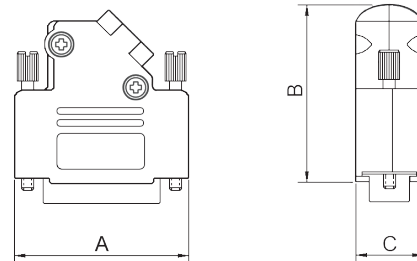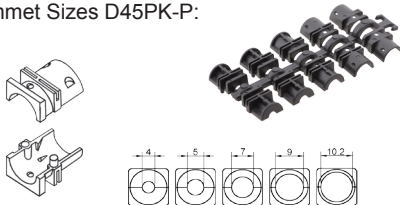

D-Sub-Hood

Size D45PK-P	Dim A	Dim B	Dim C
9-way	31,0	36,3	15,0
15-way	39,5	40,3	15,0
25-way	53,2	40,3	15,0
37-way	69,7	40,3	15,0

Ordering information:

Class 3 D-Sub Connector Kits (100 inserts min.)

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
9-way	6355-0034-11	D45PK-P-09-DBS-K
15-way	6355-0034-12	D45PK-P-15-DBS-K
25-way	6355-0034-13	D45PK-P-25-DBS-K
37-way	6355-0034-14	D45PK-P-37-DBS-K

Ordering information:

Class 1 D-Sub Connector Kits (500 inserts min.)

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
9-way	6355-0035-11	D45PK-P-09-DMS-K
15-way	6355-0035-12	D45PK-P-15-DMS-K
25-way	6355-0035-13	D45PK-P-25-DMS-K
37-way	6355-0035-14	D45PK-P-37-DMS-K