



TECHNICAL SPECIFICATIONS

D-Sub Hood:

Material:	UL Recognised Plastic Material
Plating:	Nickel over Copper
Operating Temperature:	-55°C to +105°C
Cable Entry:	Top
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D:	Up to 11,5mm

D-Sub Crimp:

Insulator:	PBT, Black, UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contact pins:	Copper Alloy
Machined pins Class 2:	200 inserts min
Contacts Plating:	Hard Gold over Nickel
Operating Temperature:	-55°C to +125°C
Test voltage:	1000V
Insulator resistance:	<5GΩ
Crimp Area (AWG):	AWG 24-20 0.2 - 0.6mm ²

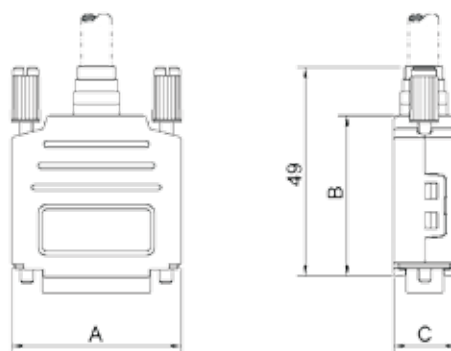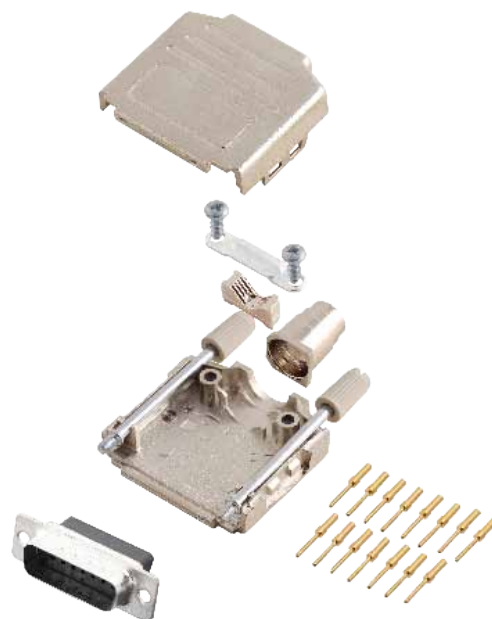

D-Sub-Hood

Features:

- Available in sizes 9, 15, 25 and 37-way
- Suitable for any common Sub-D Connector
- Quick-Snap locking system
- Supplied No. of pins = size of connector
- Re-openable
- Recyclable

Size DPPK-M	Dim A	Dim B	Dim C
9-way	32,5	38,0	15,0
15-way	41,0	38,0	15,0
25-way	54,5	40,0	15,0
37-way	71,0	40,0	15,0

Ordering information:**D-Sub Connector Kits (200 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
9-way	6355-0052-01	DPPK09-M-DBCP-K
15-way	6355-0052-02	DPPK15-M-DBCP-K
25-way	6355-0052-03	DPPK25-M-DBCP-K
37-way	6355-0052-04	DPPK37-M-DBCP-K

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
9-way	6355-0052-11	DPPK09-M-DBCS-KK
15-way	6355-0052-12	DPPK15-M-DBCS-KK
25-way	6355-0052-13	DPPK25-M-DBCS-KK
37-way	6355-0052-14	DPPK37-M-DBCS-KK

