

## TECHNICAL SPECIFICATIONS

**D-Sub Hood:**


|                        |                            |
|------------------------|----------------------------|
| Material:              | UL 94 V-0 Plastic Material |
| Operating Temperature: | -55°C to +110°C            |
| Cable Entry:           | Top                        |
| Thumbscrews:           | UNC 4-40 (Standard)        |
| Cable O.D:             | Up to 11,5mm               |
| Colour:                | Black                      |

**D-Sub High Density:**


|                        |                            |
|------------------------|----------------------------|
| Insulator:             | PBT, Black, UL94 V-0       |
| Shell:                 | Stamped Steel, Tin Plated  |
| Contact pins:          | Copper Alloy               |
| Stamped & Formed pins: | 100 inserts min            |
| Contacts Plating:      | Selective Gold over Nickel |
| Operating Temperature: | -55°C to +105°C            |
| Withstanding voltage:  | 500V for 1 minute          |
| Insulator resistance:  | 500MΩ min                  |

**Features:**

- Available in sizes 9-15-25-37
- Suitable for any common Sub-D connector
- Strain relief inserts ensure a secure termination
- Re-openable

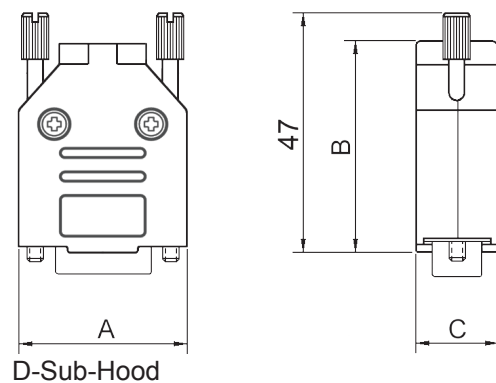

D-Sub-Hood

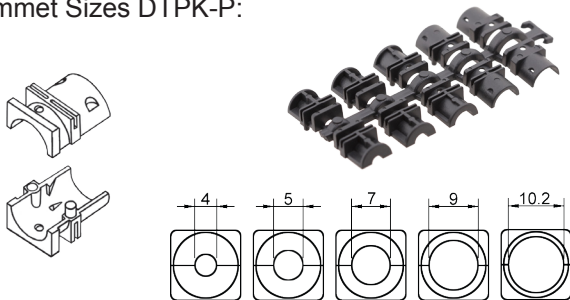**Grommet Sizes DTPK-P:**

| Size DTPK-P | Dim A | Dim B | Dim C |
|-------------|-------|-------|-------|
| 9-way       | 31,2  | 39,9  | 15,0  |
| 15-way      | 39,5  | 41,5  | 15,0  |
| 25-way      | 53,4  | 48,6  | 15,0  |
| 37-way      | 69,7  | 53,6  | 15,0  |

**Ordering information:****D-Sub Connector Kits (100 inserts min.)**

| Size: | P/N - Kitted: | Product Code - MALE Conn. Kit |
|-------|---------------|-------------------------------|
| HD 15 | 6355-0053-01  | DTPK-P-09-HDP15-K             |
| HD 26 | 6355-0053-02  | DTPK-P-15-HDP26-K             |
| HD 44 | 6355-0053-03  | DTPK-P-25-HDP44-K             |
| HD 62 | 6355-0053-04  | DTPK-P-37-HDP62-K             |

| Size: | P/N - Kitted: | Product Code - FEMALE Conn. Kit |
|-------|---------------|---------------------------------|
| HD 15 | 6355-0053-11  | DTPK-P-09-HDS15-K               |
| HD 26 | 6355-0053-12  | DTPK-P-15-HDS26-K               |
| HD 44 | 6355-0053-13  | DTPK-P-25-HDS44-K               |
| HD 62 | 6355-0053-14  | DTPK-P-37-HDS62-K               |