

TECHNICAL SPECIFICATIONS

D-Sub Hood:

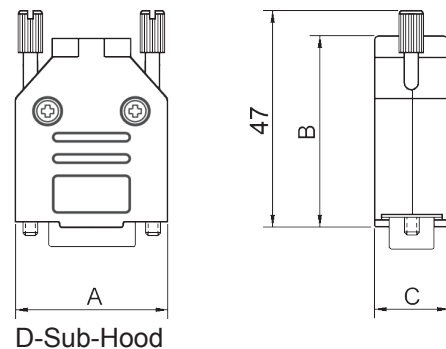
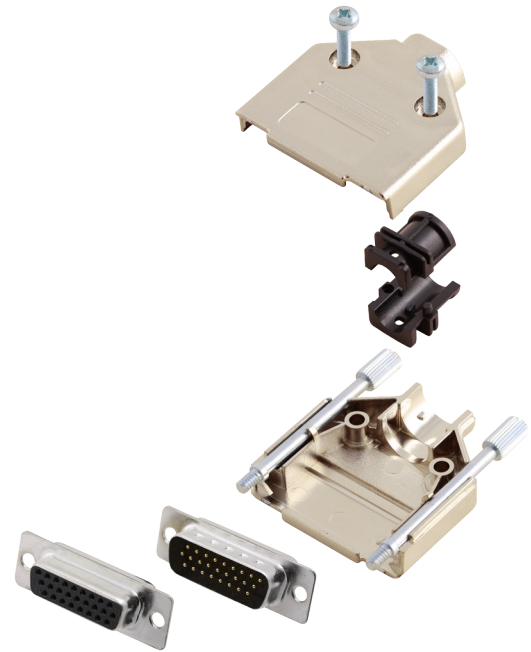
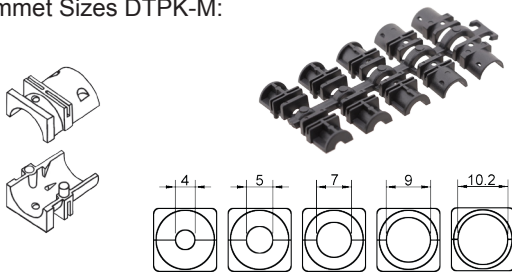
Material:	UL 94 V-0 Plastic Material
Plating:	Nickel over Copper
Operating Temperature:	-55°C to +110°C
Cable Entry:	Top Entry
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D:	Up to 11,5mm

D-Sub High Density:

Insulator:	PBT, Black, UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed pins:	100 inserts min
Contacts Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	500V for 1 minute
Insulator resistance:	500MΩ min

Features:

- Available in sizes 9-15-25-37
- Suitable for any common Sub-D Connector
- Strain relief inserts ensure a secure termination
- Re-openable
- Recyclable

**Grommet Sizes DTPK-M:**

Size DTPK-M	Dim A	Dim B	Dim C
9-way	31,2	39,9	15,0
15-way	39,5	41,5	15,0
25-way	53,4	48,6	15,0
37-way	69,7	53,6	15,0

Ordering information:**D-Sub Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
HD 15	6355-0056-01	DTPK-M-09-HDP15-K
HD 26	6355-0056-02	DTPK-M-15-HDP26-K
HD 44	6355-0056-03	DTPK-M-25-HDP44-K
HD 62	6355-0056-04	DTPK-M-37-HDP62-K

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
HD 15	6355-0056-11	DTPK-M-09-HDS15-K
HD 26	6355-0056-12	DTPK-M-15-HDS26-K
HD 44	6355-0056-13	DTPK-M-25-HDS44-K
HD 62	6355-0056-14	DTPK-M-37-HDS62-K