



TECHNICAL SPECIFICATIONS

D-Sub Hood:

Material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	90° Side Entry
Jackscrews:	UNC 4-40
Cable O.D:	Up to 11,5mm
Type of grommets:	2 piece Plastic Ferrule Kit

D-Sub High Density:

Insulator:	PBT, Black, UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed pins:	100 inserts min
Contacts Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	500V for 1 minute

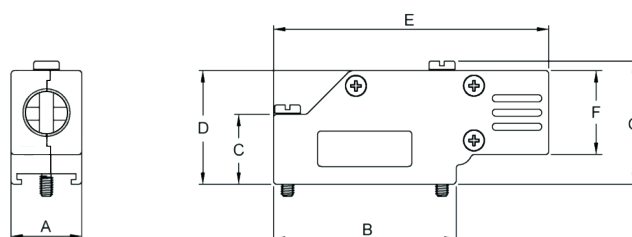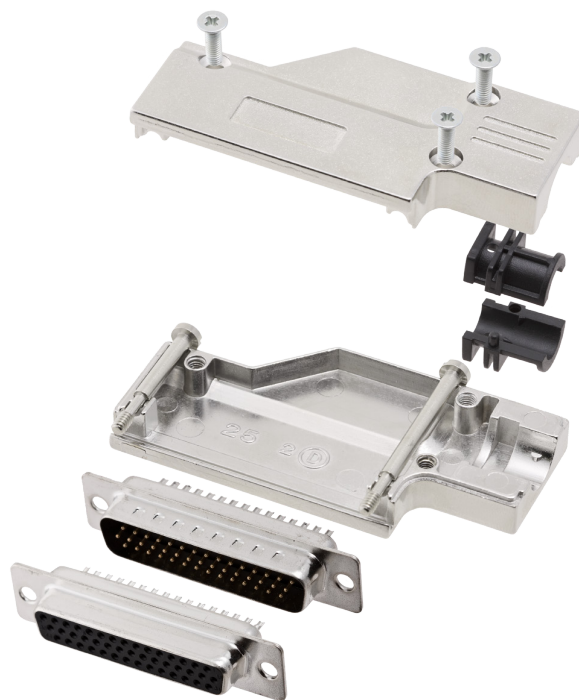

D-Sub-Hood

Features:

- Available in sizes 15-26-44-62
Other sizes on request
- Suitable for any common Sub-D connector
- Re-Openable

Size	A	B	C	D	E	F	G
9	15,0	31,0	15,0	24,0	51,0	18,0	26,5
15	15,3	39,2	15,0	24,0	59,0	18,0	26,5
25	16,0	54,0	23,0	34,5	73,0	24,5	37,0
37	16,0	70,5	23,0	34,5	89,5	24,5	37,0

Ordering information:**D-Sub Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
HD 15	6355-0066-01	DCMR09-FK-HDP15-K
HD 26	6355-0066-02	DCMR15-FK-HDP26-K
HD 44	6355-0066-03	DCMR25-FK-HDP44-K
HD 62	6355-0066-04	DCMR37-FK-HDP62-K

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
HD 15	6355-0066-11	DCMR09-FK-HDS15-K
HD 26	6355-0066-12	DCMR15-FK-HDS26-K
HD 44	6355-0066-13	DCMR25-FK-HDS44-K
HD 62	6355-0066-14	DCMR37-FK-HDS62-K